


# E11553



## Female wirable connectors

SDOGF040MSSFPKG

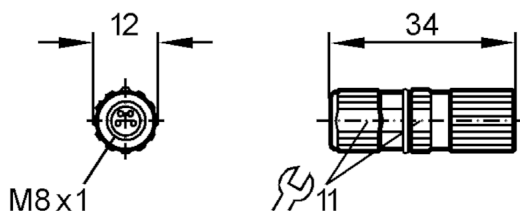

### Application

Special feature	gold-plated contacts
-----------------	----------------------

### Electrical data

Operating voltage	[V]	< 45 AC / < 70 DC
Protection class		III
Max. current load total	[A]	4

### Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

### Mechanical data

Weight	[g]	17.1
Material		Core insulation: PVC / TPE
Molded-body material		PA
Material nut		brass, nickel-plated

### Remarks

Pack quantity	1 pcs.
---------------	--------

### Electrical connection

insulation displacement technology: 0.14...0.38 mm<sup>2</sup>; Core insulation: PVC / TPE; (Ø 1.0...1.6 mm); Cable sheath: Ø 3...5 mm

### Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Contacts: 4, gold-plated; Moulded body: PA; Locking: brass, nickel-plated



# E11553



## Female wirable connectors

SDOGF040MSSFPKG

### Connection

