

E11562




Y/T splitter

T SPLITTER M12/2XUS

Article no longer available - archive entry

Alternative articles: EBC113
When selecting an alternative article and accessories please note that technical data may differ!

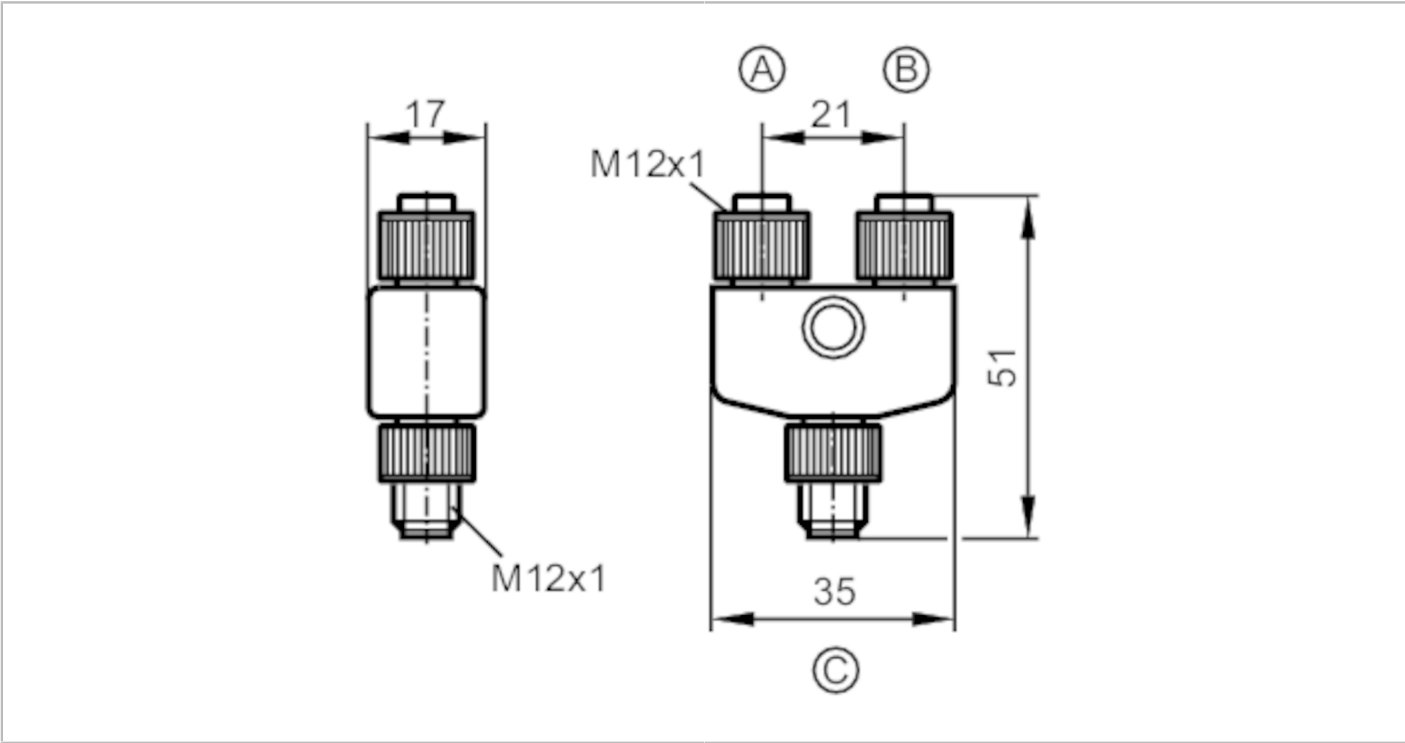

Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load per module/slot	[A]	4
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Weight	[g]	34.8
Material		PUR
Remarks		
Pack quantity		1 pcs.

E11562



Y/T splitter

T SPLITTER M12/2XUS

Electrical connection

Connection

