


# E11564



## Connection cable

VDOAF032MSS01,5H03STGH030MSS

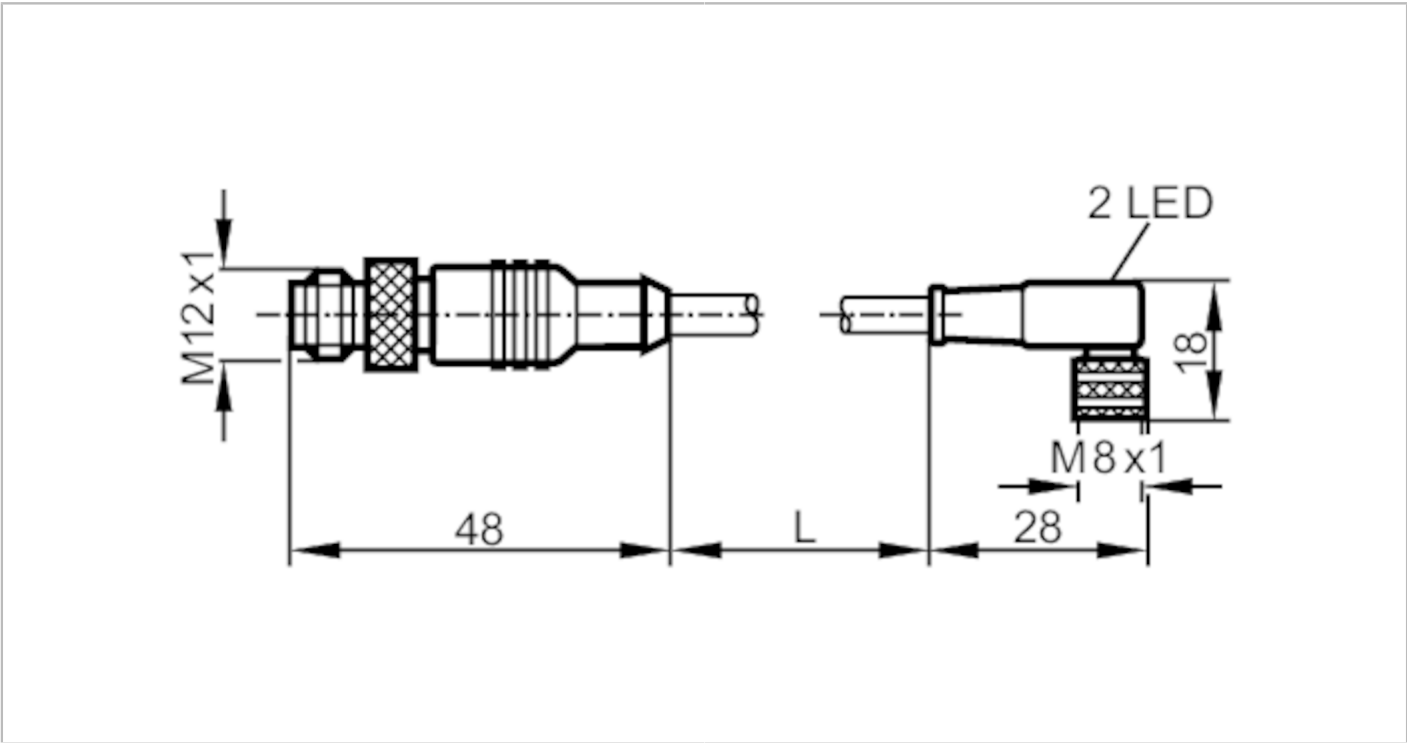

| Application                   |                                                        |                      |
|-------------------------------|--------------------------------------------------------|----------------------|
| System                        | Free from silicone; Halogen-free; gold-plated contacts |                      |
| Free from silicone            | yes                                                    |                      |
| Electrical data               |                                                        |                      |
| Operating voltage             | [V]                                                    | 10...30 DC           |
| Protection class              |                                                        | III                  |
| Max. current load total       | [A]                                                    | 3                    |
| Outputs                       |                                                        |                      |
| Electrical design             | PNP                                                    |                      |
| Operating conditions          |                                                        |                      |
| Ambient temperature           | [°C]                                                   | -25...85             |
| Protection                    |                                                        | IP 68                |
| Mechanical data               |                                                        |                      |
| Weight                        | [g]                                                    | 56.2                 |
| Material                      |                                                        | PUR                  |
| Molded-body material          |                                                        | PUR                  |
| Material nut                  |                                                        | brass, nickel-plated |
| Displays / operating elements |                                                        |                      |
| Display                       | Switching status                                       | 1 x LED, yellow      |
|                               | Power                                                  | 1 x LED, green       |
| Remarks                       |                                                        |                      |
| Pack quantity                 | 1 pcs.                                                 |                      |

# E11564



## Connection cable

VDOAF032MSS01,5H03STGH030MSS

### Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



### Electrical connection

Cable: 1.5 m, PUR, Halogen-free, black, Ø 5 mm; 3 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

#### Connection



### Electrical connection - Buchse



# E11564



## Connection cable

VDOAF032MSS01,5H03STGH030MSS

### Connection



### Electrical connection - Socket

Connector: 1 x M8, angled; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm