




Y/T splitter

Safety splitter box

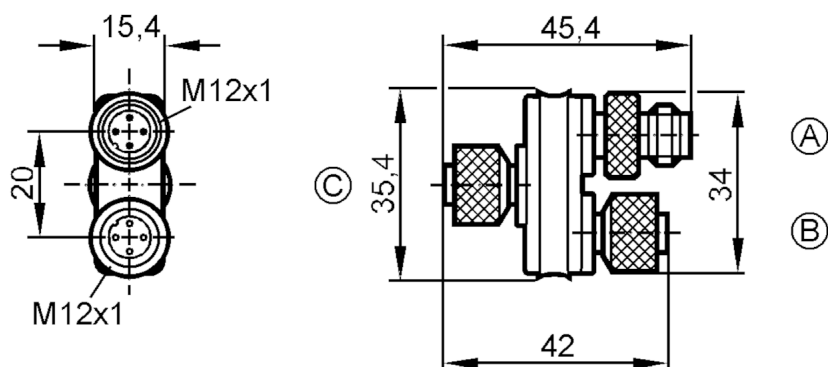

Application

Design	T-piece for the pseudo-serial connection of fail-safe sensors
--------	---

Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load per module/slot	[A]	4
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Weight	[g]	31.4
Material		PUR
Molded-body material		PUR
Material nut		brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

E11569




Y/T splitter

Safety splitter box

Electrical connection

Connection

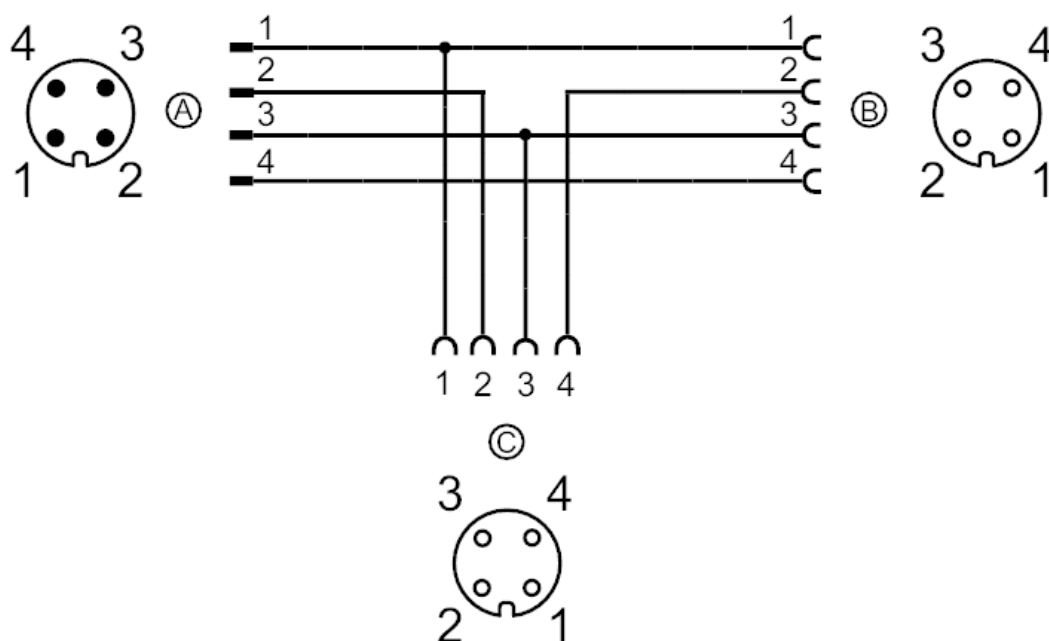

Electrical connection - Socket

Connector: 1 x M12; Moulded body: PUR; Locking: brass, nickel-plated

Connector: 1 x M12; Moulded body: PUR; Locking: brass, nickel-plated

Electrical connection - plug

Connector: 1 x M12; Moulded body: PUR; Locking: brass, nickel-plated