


E11572



Connection cable

VDOGQ090PLS0003E03STGF040MSS

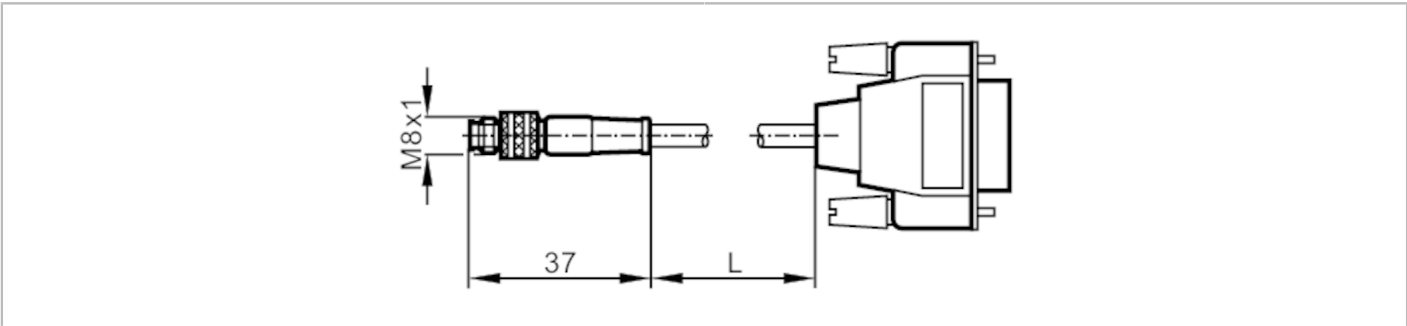

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 50

Mechanical data

Weight	[g]	113.9
Material		PUR
Molded-body material		PUR
Material nut		brass, nickel-plated

Remarks


Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

Cable: 3 m, PVC, black, Ø 5 mm; 3 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x Sub D, straight; Moulded body: PUR; Locking: brass, nickel-plated

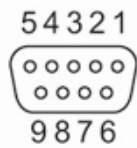

Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



E11572



Connection cable

VDOGQ090PLS0003E03STGF040MSS

Connection

