


E11586



Male cordsets

ASTGH040VAS0005E04

Article no longer available - archive entry

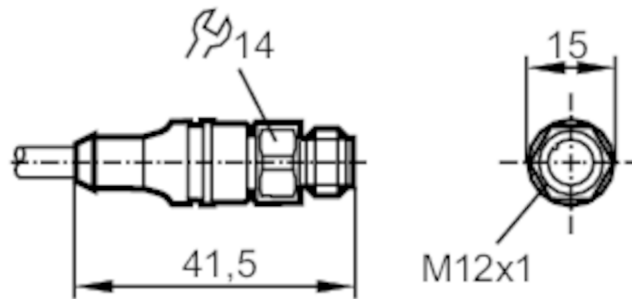


Application	
System	Free from silicone; gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 250 AC / < 300 DC
Operating conditions	
Ambient temperature [°C]	-25...100
Protection	IP 68; IP 69K
Mechanical data	
Dimensions [mm]	15 x 15 x 41.5
Material	PVC
Material nut	stainless steel (1.4404 / 316L)
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 5 m, PVC, orange, Ø 5.3 mm; 4 x 0.34 mm ² (42 x Ø 0.1 mm)	
Electrical connection - plug	
Connector: 1 x M12, straight; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm	

E11586



Male cordsets

 ASTGH040VAS0005E04



Connection

1	BN
2	WH
3	BU
4	BK

Core colors :

BK =	black
BN =	brown
BU =	blue
WH =	white

Article no longer available - archive entry