


# E11590



## Plug with CAN bus terminating resistor

 
SSTGH050ZDAFKPG

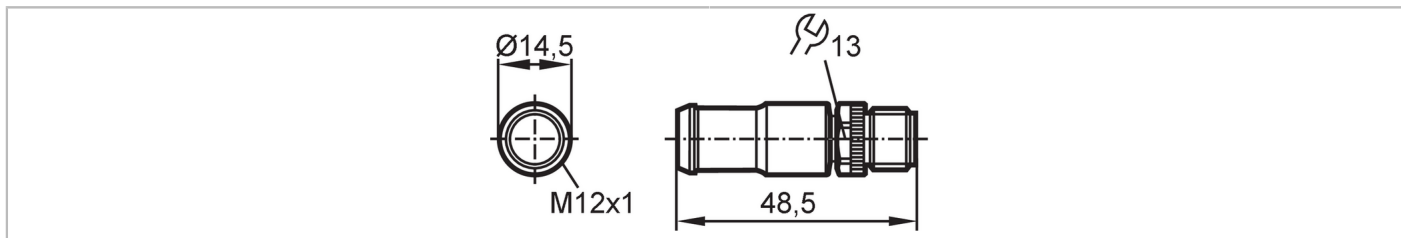

Application	
Special feature	gold-plated contacts
Application	CAN bus; for mobile applications
Operating conditions	
Ambient temperature [°C]	-40...85
Protection	IP 68
Mechanical data	
Weight [g]	8.39
Dimensions [mm]	14.5 x 14.5 x 48.5
Molded-body material	TPU (urethane)
Material nut	diecast zinc, nickel-plated
Remarks	
Remarks	The CAN bus terminating resistor (120 Ω) is integrated in the M12 connector.
Pack quantity	1 pcs.

### Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Contacts: 5, gold-plated; Moulded body: TPU (urethane); Locking: diecast zinc, nickel-plated; Tightening torque: ...0.6 Nm



### Connection

