


E11596



Female cordset

ADOGH050MSA0002C02

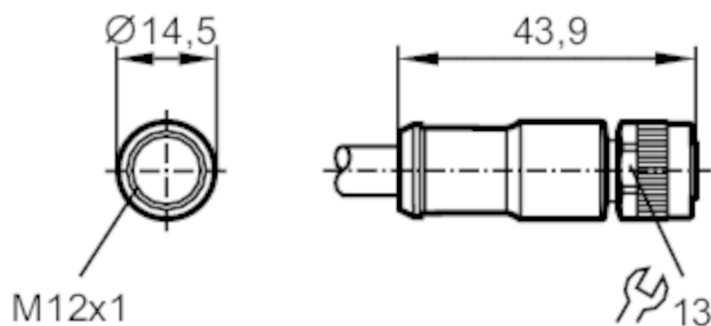

Application

System	Halogen-free; gold-plated contacts; screened cable; Drag chain suitability
Application	CAN bus

Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-20...80
Storage temperature	[°C]	-40...80
Protection		IP 68

Mechanical data

Weight	[g]	163
Dimensions	[mm]	14.5 x 14.5 x 43.9
Material		PUR
Molded-body material		PUR
Material nut		brass, nickel-plated
Drag chain suitability		yes
Drag chain suitability	Bending radius for flexible applications	min. 10 x cable diameter
	Bending radius for fixed installation	min. 5 x cable diameter
	Travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s²
	Bending cycles	> 1 Mio.

Remarks

Pack quantity	1 pcs.
---------------	--------

E11596



Female cordset


ADOGH050MSA0002C02

Electrical connection


Cable: 2 m, PUR, Halogen-free, lilac, Ø 6.8 mm, screened; RD / BK: 2 x 0.25 mm² (19 x Ø 0.13 mm) + WH / BU: 2 x 0.34 mm² (19 x Ø 0.16 mm) + screen: 1 x 0.34 mm² (19 x Ø 0.16 mm)

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated

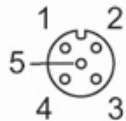

Connection

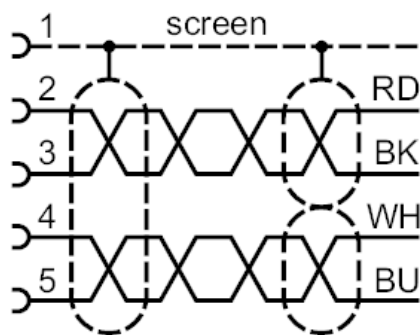

	Core colors :
BK =	black
BU =	blue
RD =	red
WH =	white
screen =	screen