


E11622



Patchcords with valve plug

VVDAA040MSS0002H03STGH020MSS

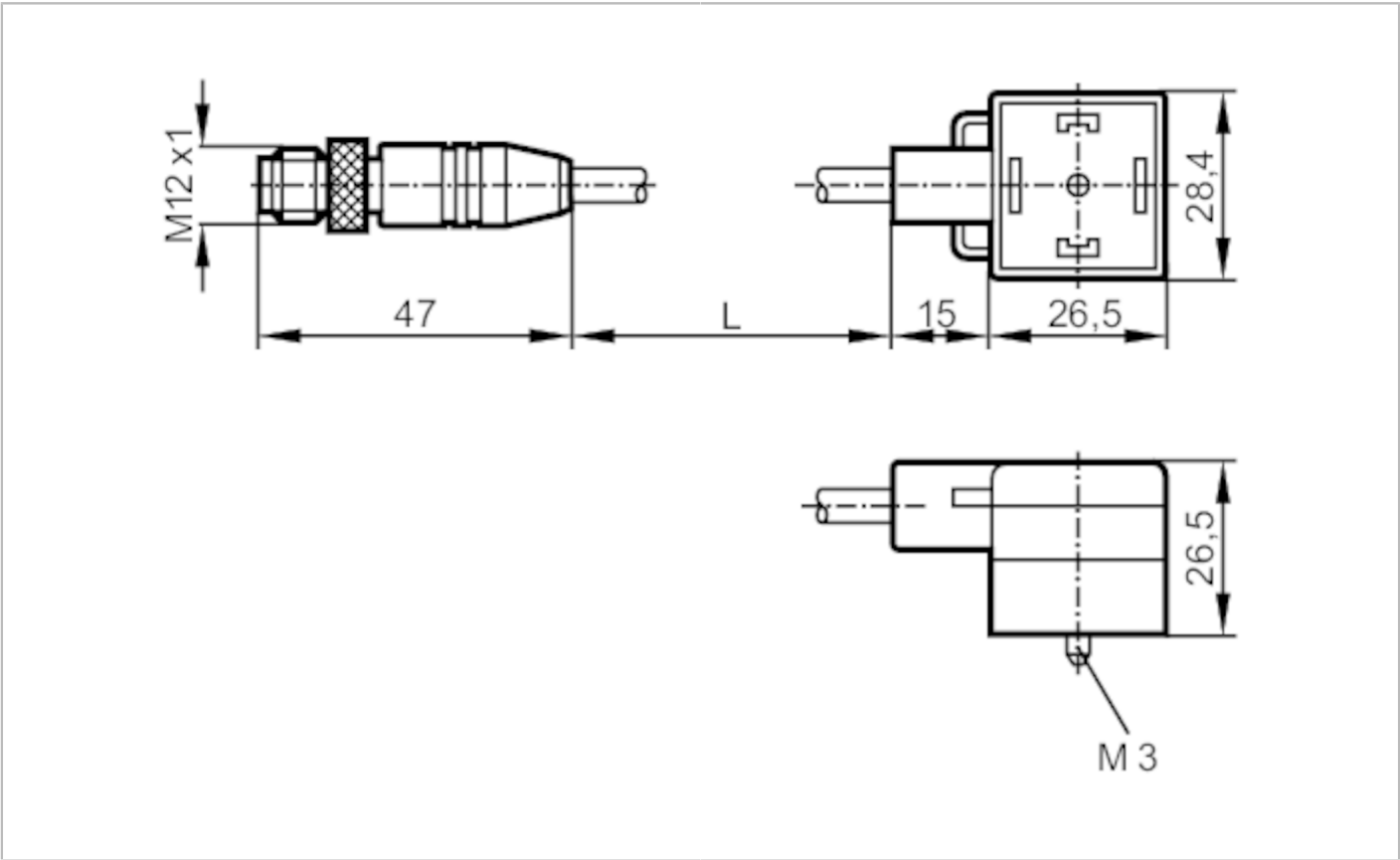

Application		
Application		current measurement
Electrical data		
Operating voltage	[V]	< 24 AC/DC
Operating conditions		
Ambient temperature	[°C]	-40...90
Protection		IP 67; IP 69K
Mechanical data		
Weight	[g]	152.5
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Accessories		
Items supplied		screw
		panel for labelling
Remarks		
Pack quantity		1 pcs.

E11622



Patchcords with valve plug

VVDAA040MSS0002H03STGH020MSS

Electrical connection - plug

 
Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Electrical connection

Cable: 2 m, PUR; 2 x 0.75 mm²

Connection



Electrical connection - Socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

