

E11643




Connection cable

VDOGH050VAS0002E05STGH050VAS

Article no longer available - archive entry

Alternative articles: EVT061
When selecting an alternative article and accessories please note that technical data may differ!

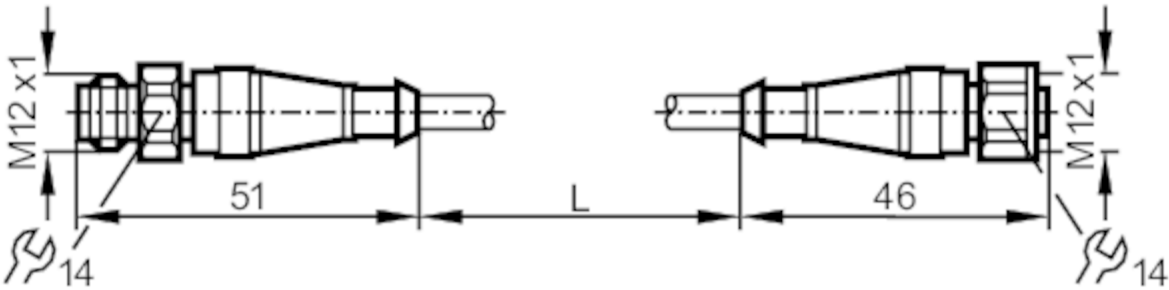

Application	
System	Free from silicone; gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 30 AC / < 36 DC
Max. current load total [A]	4
Operating conditions	
Ambient temperature [°C]	-25...100
Protection	IP 68; IP 69K
Mechanical data	
Material	PVC
Molded-body material	PVC
Material nut	stainless steel (1.4404 / 316L)
Remarks	
Pack quantity	1 pcs.

E11643



Connection cable


VDOGH050VAS0002E05STGH050VAS

Electrical connection

Cable: 2 m, PVC, orange, Ø 5.3 mm; 5 x 0.25 mm² (32 x Ø 0.1 mm)


Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated;
Tightening torque: 0.7...0.9 Nm

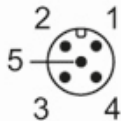

Electrical connection

Connection

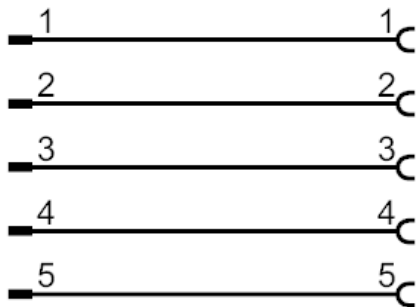

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated;
Tightening torque: 0.7...0.9 Nm

