

E11664




Y connection cable

YDOAH040MSS0,25H04STGH040MSS

Article no longer available - archive entry

Alternative articles: EVC503

When selecting an alternative article and accessories please note that technical data may differ!

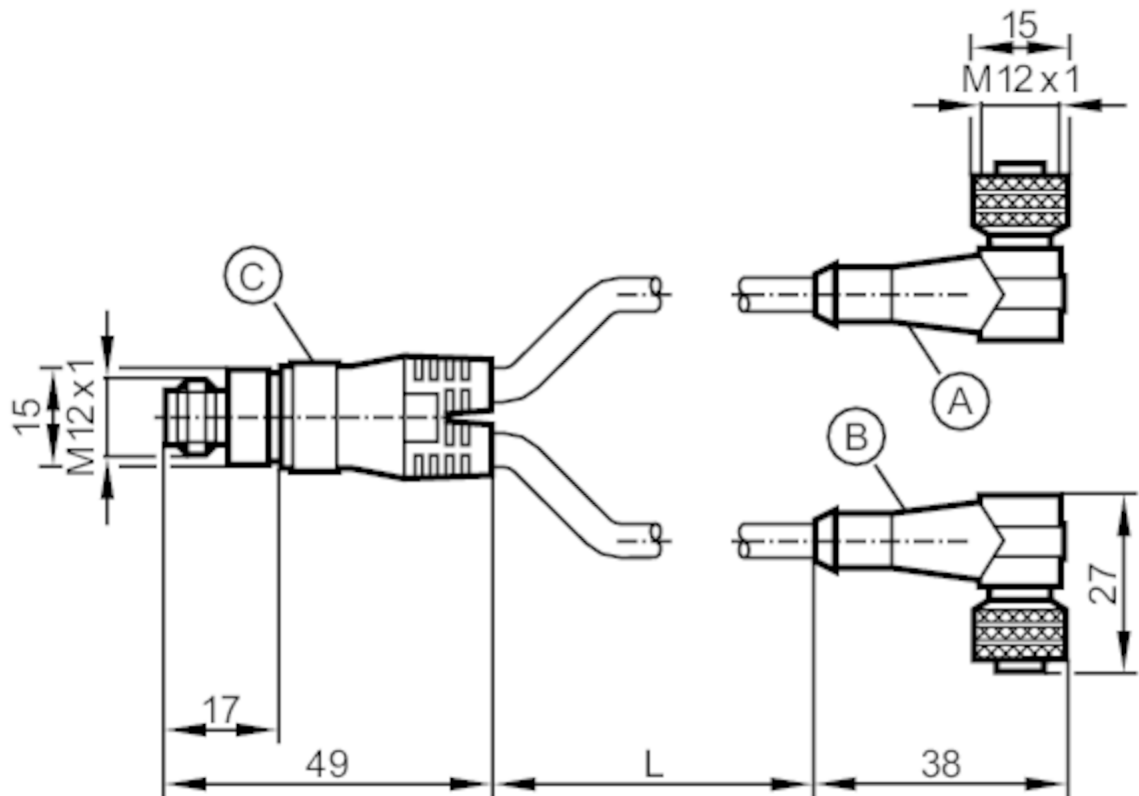

3-1 input cable grey
3-2 octavis cable black

Application

System	Halogen-free
--------	--------------

Electrical data

Operating voltage	[V]	10...30 DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Weight	[g]	65
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Number of ports splitter box		2

Remarks

Pack quantity	1 pcs.
---------------	--------

E11664



Y connection cable

YDOAH040MSS0,25H04STGH040MSS

Electrical connection

Cable: 0.25 m, PUR, Halogen-free, black, Ø 5 mm; 5 x 0.25 mm² (32 x Ø 0.1 mm)


Electrical connection - Socket

Connector: 2 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

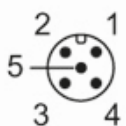

Connection

