


E11686



Bulk cable

CABLE/100M/ PUR/4X0,34/BK

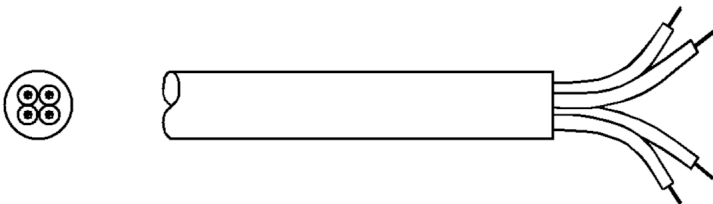

Application		
System	Halogen-free; Drag chain suitability	
Operating conditions		
Ambient temperature	[°C]	-40...90
Mechanical data		
Weight	[g]	3127
Drag chain suitability	yes	
Drag chain suitability	Bending radius for flexible applications	min. 10 x cable diameter
	Travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s²
	Bending cycles	> 5 Mio.
	Torsional strain	± 180 °/m
Remarks		
Pack quantity	1 pcs.	
Electrical connection		
Cable: 100 m, PUR, Halogen-free, black, Ø 4.9 mm; 4 x 0.34 mm², PP		