


E11693



Female cordset

ADOAH040MSN0002A04

Article no longer available - archive entry

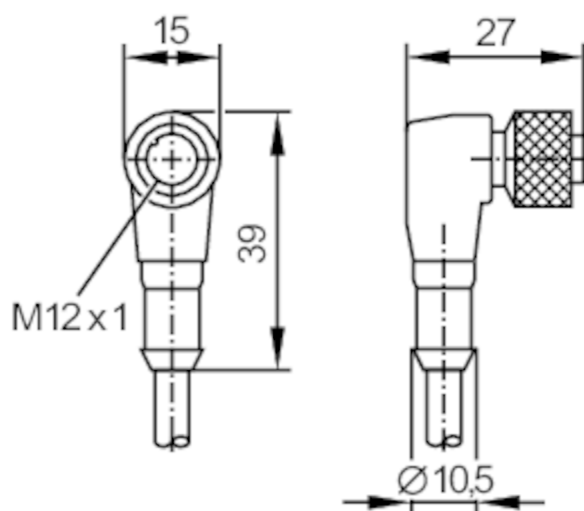

Application

Application	Ex zone 1
-------------	-----------

Electrical data

Operating voltage	[V]	< 15 DC
-------------------	-----	---------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	27 x 15 x 39
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated

Remarks

Remarks	When using sockets in hazardous areas (ATEX) there are special requirements regarding wiring.
	The requirements of the applicable installation regulations must be absolutely adhered to by the user on his own responsibility.
Pack quantity	1 pcs.

E11693



Female cordset


ADOAH040MSN0002A04

Electrical connection


Cable: 2 m, PUR / PVC, blue, Ø 5 mm; 5 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

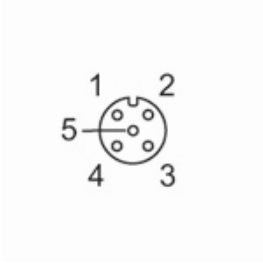

Connection

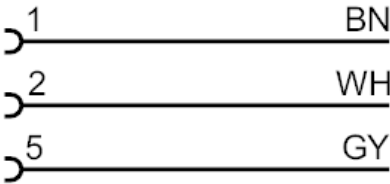

BN = Core colors :
brown
GY = grey
WH = white