


# E11694



## Female cordset

ADOAH040MSN0005A04

Article no longer available - archive entry

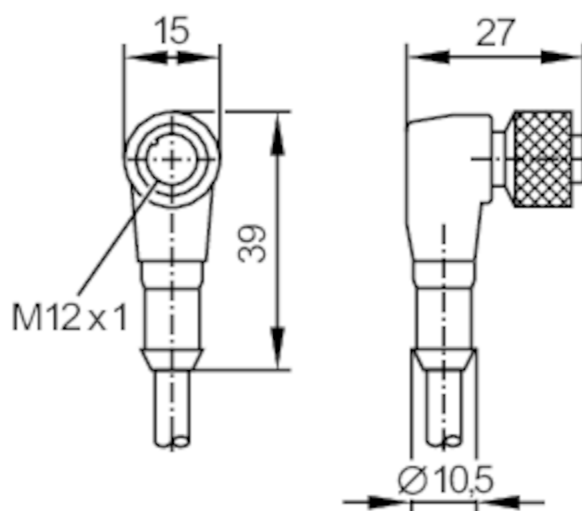

### Application

Application	Ex zone 1
-------------	-----------

### Electrical data

Operating voltage	[V]	< 15 DC
-------------------	-----	---------

### Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

### Mechanical data

Dimensions	[mm]	27 x 15 x 39
------------	------	--------------

Material	TPU (urethane)
----------	----------------

Molded-body material	TPU (urethane)
----------------------	----------------

Material nut	brass, nickel-plated
--------------	----------------------

### Remarks

Remarks	When using sockets in hazardous areas (ATEX) there are special requirements regarding wiring. The requirements of the applicable installation regulations must be absolutely adhered to by the user on his own responsibility.
---------	-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------

Pack quantity	1 pcs.
---------------	--------

# E11694



## Female cordset


ADOAH040MSN0005A04

### Electrical connection


Cable: 5 m, PUR / PVC, blue, Ø 5 mm; 5 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

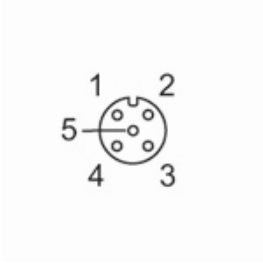

### Connection

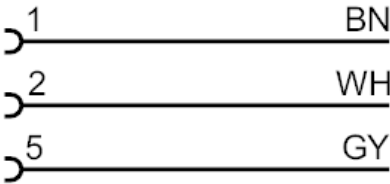

BN = Core colors : brown  
GY = grey  
WH = white