

E11716




Wirable plug

SSTGH050VASFPKG

Article no longer available - archive entry

Alternative articles: E11859
When selecting an alternative article and accessories please note that technical data may differ!

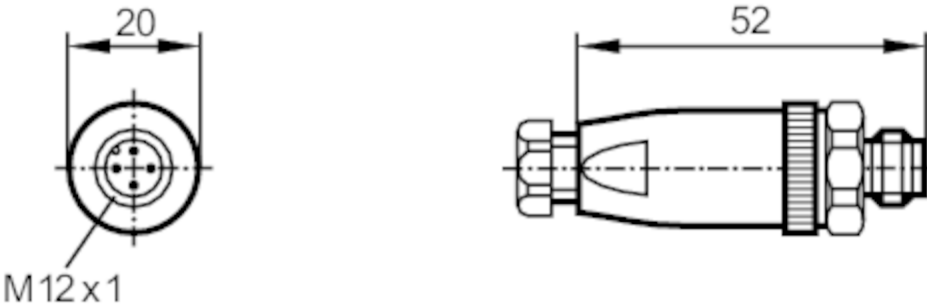

Application		
System		Free from silicone; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 125 AC/DC
Max. current load total	[A]	4; (...40 °C)
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 67
Mechanical data		
Dimensions	[mm]	20 x 20 x 52
Material		PA
Molded-body material		PA
Material nut		stainless steel (1.4571/316Ti)
Remarks		
Pack quantity		1 pcs.

E11716



Wirable plug


SSTGH050VASFPKG

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 6...8 mm

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated

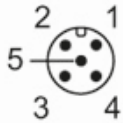

Connection

