




Wiring block

ZDO4H050MSS0005H07

Article no longer available - archive entry

Alternative articles: EBC013
When selecting an alternative article and accessories please note that technical data may differ!

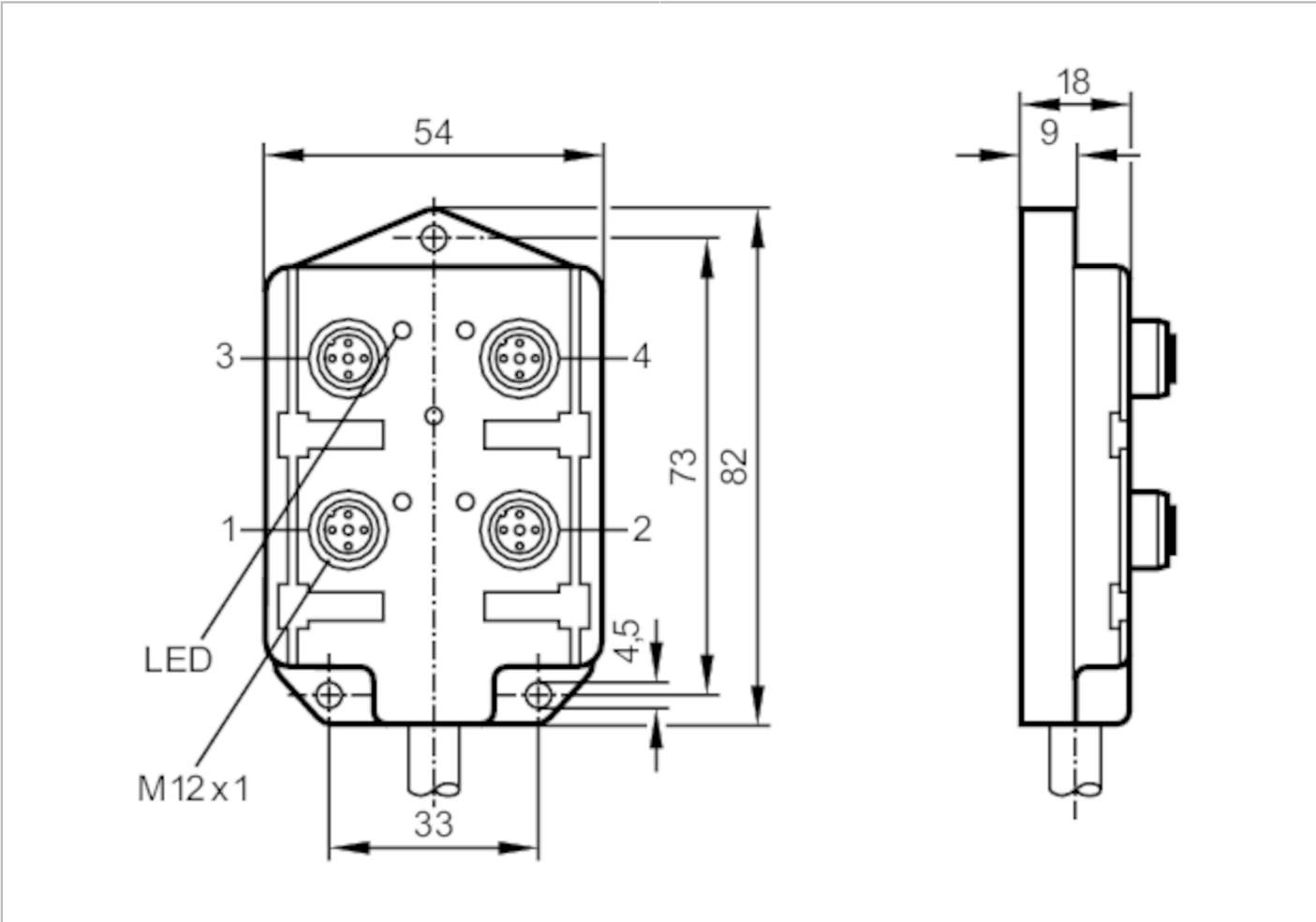

Application		
System	Free from silicone; Halogen-free; gold-plated contacts	
Free from silicone	yes	
Electrical data		
Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12
Operating conditions		
Ambient temperature	[°C]	-15...80
Protection		IP 67
Mechanical data		
Dimensions	[mm]	18 x 54 x 82
Material		TPU (urethane)
Molded-body material		TPU (urethane)

E11717



Wiring block

ZDO4H050MSS0005H07


Number of ports splitter box	4
Connector type	M12
Remarks	
Pack quantity	1 pcs.

Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 8.4 mm; 4 x 0.34 mm² (43 x Ø 0.1 mm) + 3 x 0.75 mm² (95 x Ø 0.1 mm)

Electrical connection - slot

Connector: 4 x M12; coding: A; Moulded body: TPU (urethane); Contacts: gold-plated; Tightening torque: 0.5 Nm

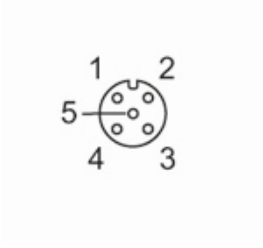

Connection

BN	1 (1...4)
BU	3 (1...4)
GN/YE	5 (1...4)
WH	4 (1)
GN	4 (2)
YE	4 (3)
GY	4 (4)

	Core colors :
BN =	brown
BU =	blue
GN =	green
GY =	grey
WH =	white
YE =	yellow