


E11718



Wiring block

ZDO4H050MSS0010H07

Article no longer available - archive entry

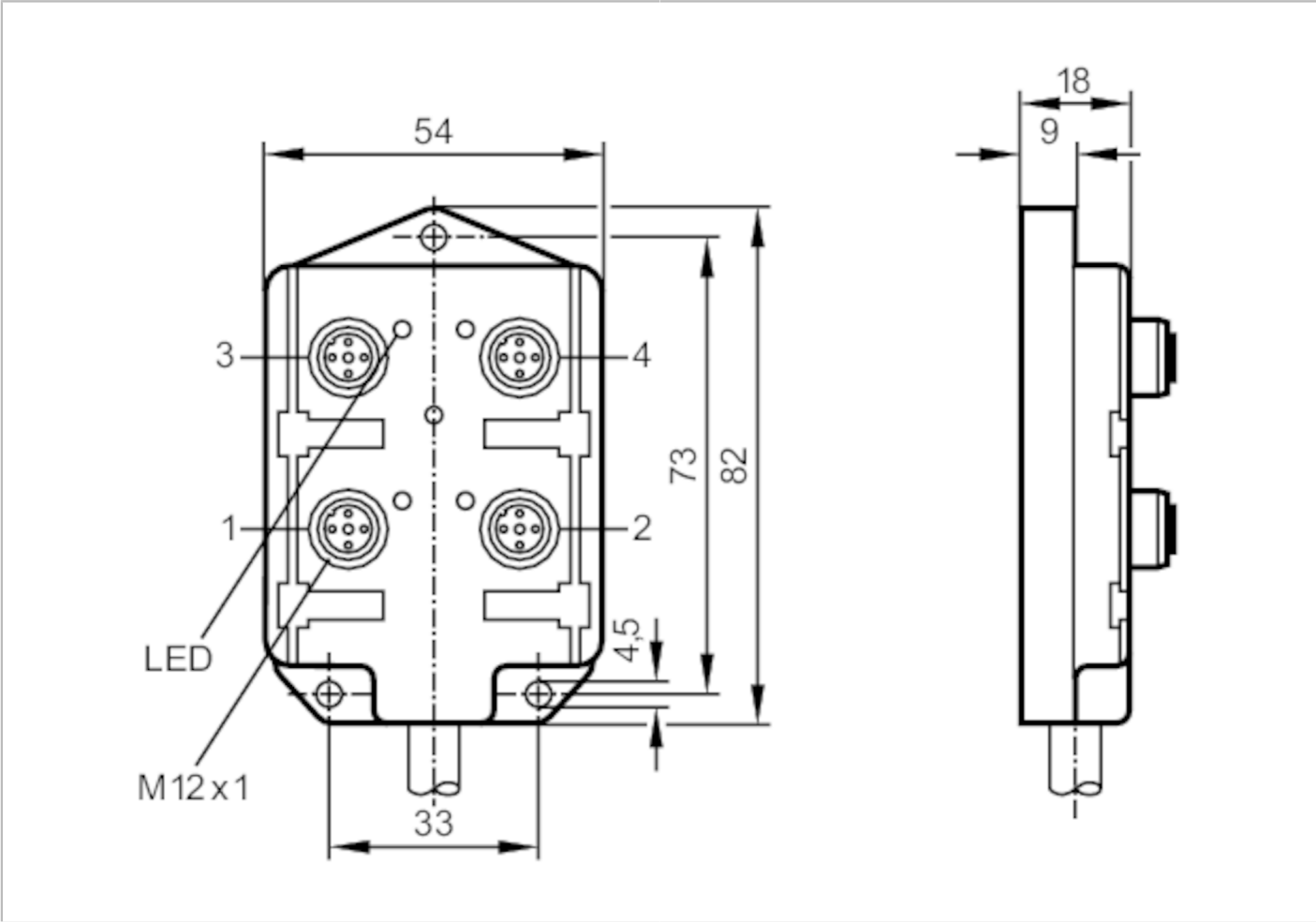

Application		
System		Free from silicone; Halogen-free; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12
Operating conditions		
Ambient temperature	[°C]	-15...80
Protection		IP 67
Mechanical data		
Dimensions	[mm]	18 x 54 x 82
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Number of ports splitter box		4
Connector type		M12

E11718



Wiring block

ZDO4H050MSS0010H07

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 10 m, PUR, Halogen-free, black, Ø 8.4 mm; 4 x 0.34 mm² (43 x Ø 0.1 mm) + 3 x 0.75 mm² (95 x Ø 0.1 mm)

Electrical connection - slot

Connector: 4 x M12; coding: A; Moulded body: TPU (urethane); Contacts: gold-plated; Tightening torque: 0.5 Nm

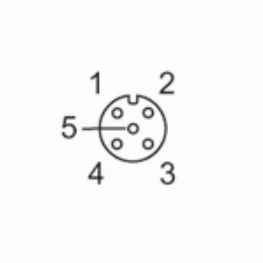

Connection

BN	1 (1...4)	C
BU	3 (1...4)	C
GN/YE	5 (1...4)	C
WH	4 (1)	C
GN	4 (2)	C
YE	4 (3)	C
GY	4 (4)	C

	Core colors :
BN =	brown
BU =	blue
GN =	green
GY =	grey
WH =	white
YE =	yellow