

E11723




Wiring block

ZDO8H050MSS0005H07

Article no longer available - archive entry

Alternative articles: EBC021
When selecting an alternative article and accessories please note that technical data may differ!

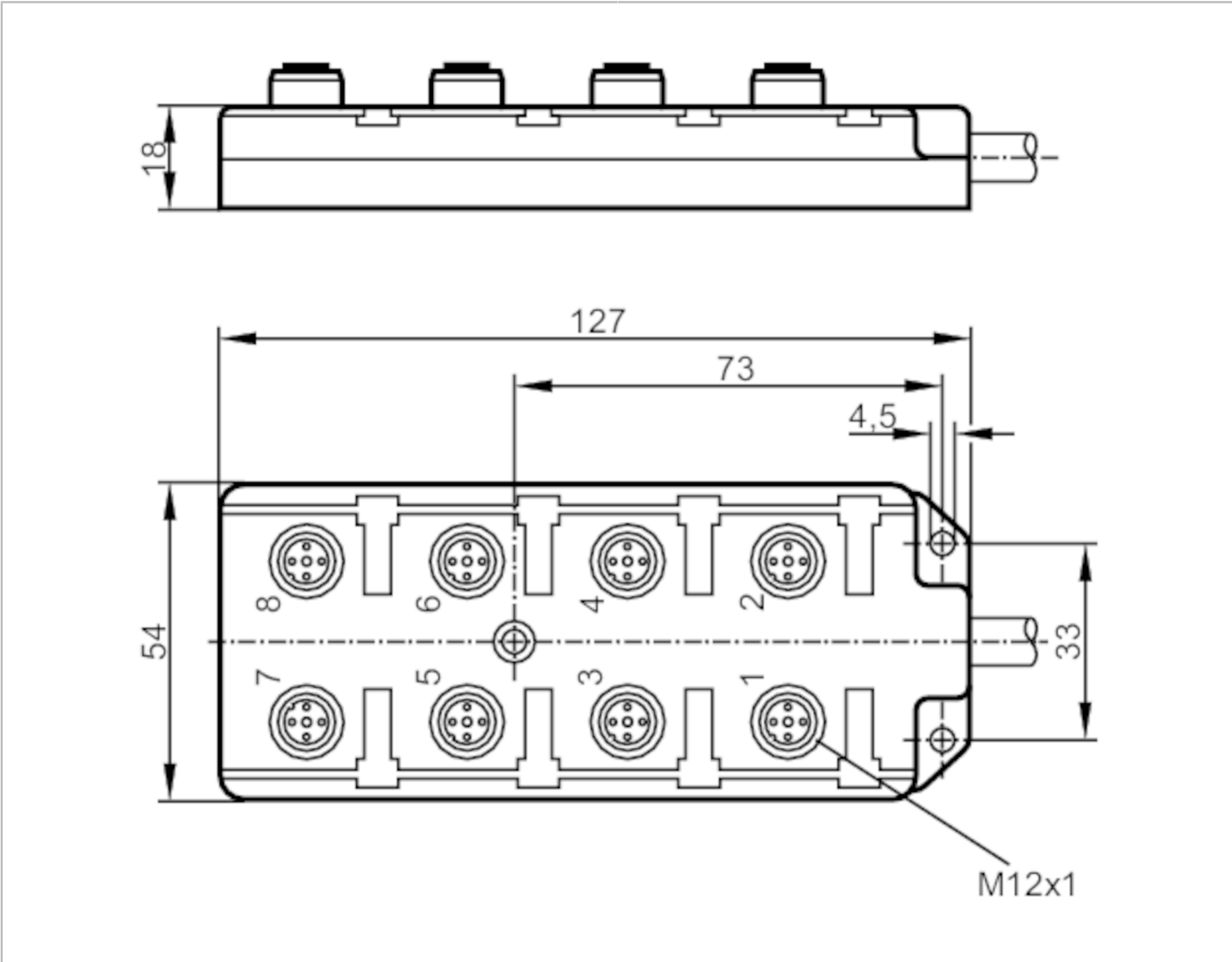

Application		
System		Free from silicone; Halogen-free; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12
Operating conditions		
Ambient temperature	[°C]	-15...80
Protection		IP 67

E11723



Wiring block

ZDO8H050MSS0005H07

Mechanical data	
Material	TPU (urethane)
Molded-body material	TPU (urethane)
Number of ports splitter box	8
Connector type	M12
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 5 m, PUR, Halogen-free, black, Ø 9 mm; 8 x 0.34 mm² (43 x Ø 0.1 mm) + 3 x 0.75 mm² (95 x Ø 0.1 mm)	
Electrical connection - slot	
Connector: 8 x M12; coding: A; Moulded body: TPU (urethane); Contacts: gold-plated; Tightening torque: 0.5 Nm	

E11723



Wiring block

ZDO8H050MSS0005H07

Connection

BN	1 (1...8)
BU	3 (1...8)
GN/YE	5 (1...8)
WH	4 (1)
GN	4 (2)
YE	4 (3)
GY	4 (4)
PK	4 (5)
RD	4 (6)
BK	4 (7)
VT	4 (8)

	Core colors :
BK =	black
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
VT =	lilac
WH =	white
YE =	yellow