

E11725




Wiring block

ZDO8H050MSS0000-00STAK120MSS

Article no longer available - archive entry

Alternative articles: EBC009
When selecting an alternative article and accessories please note that technical data may differ!

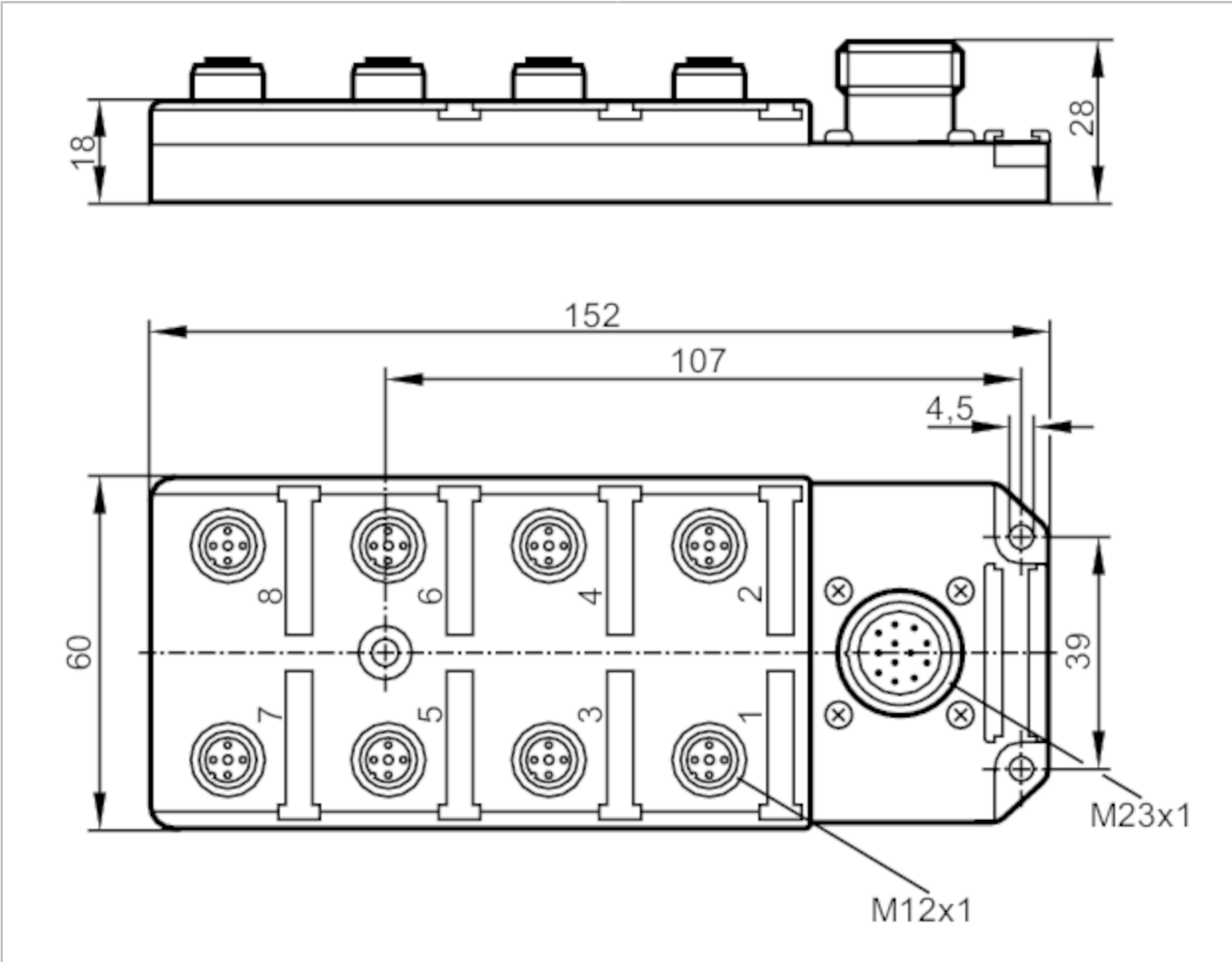

Application		
System		Free from silicone; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12
Operating conditions		
Ambient temperature	[°C]	-15...80
Protection		IP 67

E11725



Wiring block


ZDO8H050MSS0000-00STAK120MSS

Mechanical data		
Dimensions	[mm]	28 x 60 x 152
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Number of ports splitter box		8
Connector type		M12


Remarks	
Pack quantity	1 pcs.

Electrical connection - Connection

Connector: 1 x M23; Moulded body: TPU (urethane); Contacts: gold-plated; Tightening torque: 0.5 Nm

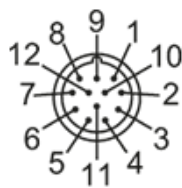

Connection

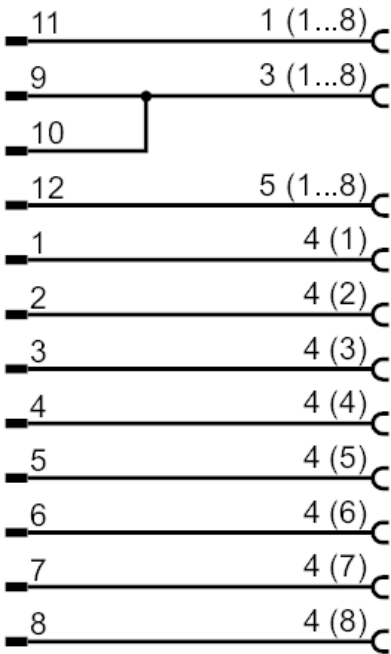

E11725



Wiring block

ZDO8H050MSS0000-00STAK120MSS

Electrical connection - slot

Connector: 8 x M12; coding: A; Moulded body: TPU (urethane); Contacts: gold-plated; Tightening torque: 0.5 Nm

