


Wiring block

ZDO4H050MSS0010H11

Article no longer available - archive entry

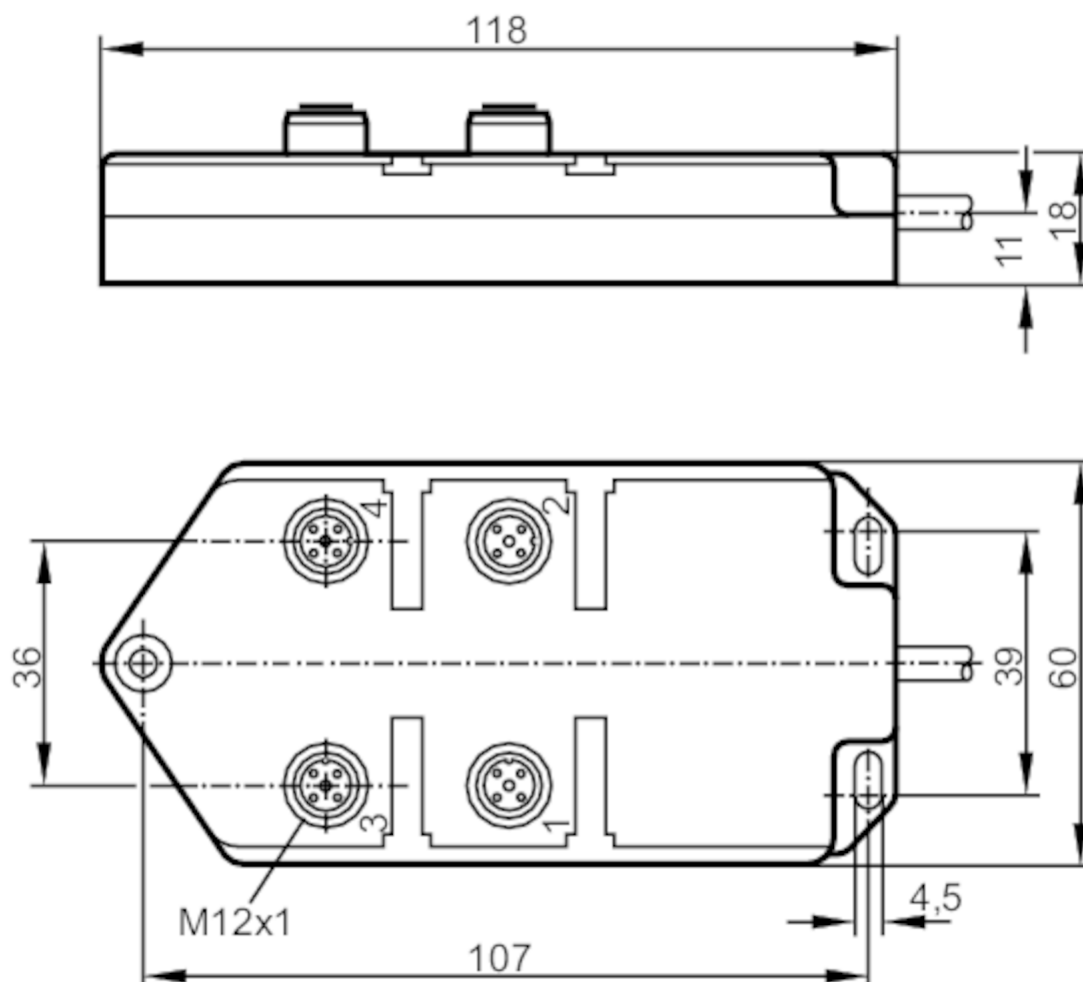

Application

System	Free from silicone; Halogen-free; gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12

Operating conditions

Ambient temperature	[°C]	-15...80
Protection		IP 67

Mechanical data

Material	TPU (urethane)
Molded-body material	TPU (urethane)

E11727



Wiring block

ZDO4H050MSS0010H11


Number of ports splitter box	4
Connector type	M12
Remarks	
Pack quantity	1 pcs.

Electrical connection

Cable: 10 m, PUR, Halogen-free, black, Ø 9.3 mm; 8 x 0.5 mm² (63 x Ø 0.1 mm) + 3 x 1.0 mm² (127 x Ø 0.1 mm)

Electrical connection - slot

Connector: 4 x M12; coding: A; Moulded body: TPU (urethane); Contacts: gold-plated; Tightening torque: 0.5 Nm

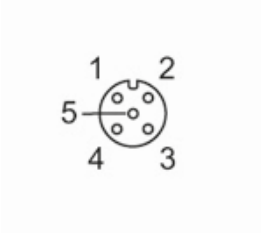

Connection

<u>BN</u>	<u>1 (1...4)</u>	<u>C</u>
<u>BU</u>	<u>3 (1...4)</u>	<u>C</u>
<u>GN/YE</u>	<u>5 (1...4)</u>	<u>C</u>
<u>GY/PK</u>	<u>2 (1)</u>	<u>C</u>
<u>RD/BU</u>	<u>2 (2)</u>	<u>C</u>
<u>WH/GN</u>	<u>2 (3)</u>	<u>C</u>
<u>BN/GN</u>	<u>2 (4)</u>	<u>C</u>
<u>WH</u>	<u>4 (1)</u>	<u>C</u>
<u>GN</u>	<u>4 (2)</u>	<u>C</u>
<u>YE</u>	<u>4 (3)</u>	<u>C</u>
<u>GY</u>	<u>4 (4)</u>	<u>C</u>

	Core colors :
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
WH =	white
YE =	yellow