

E11731




Wiring block

ZDO6H050MSS0000-00STAK190MSS

Article no longer available - archive entry

Alternative articles: EBC007
When selecting an alternative article and accessories please note that technical data may differ!

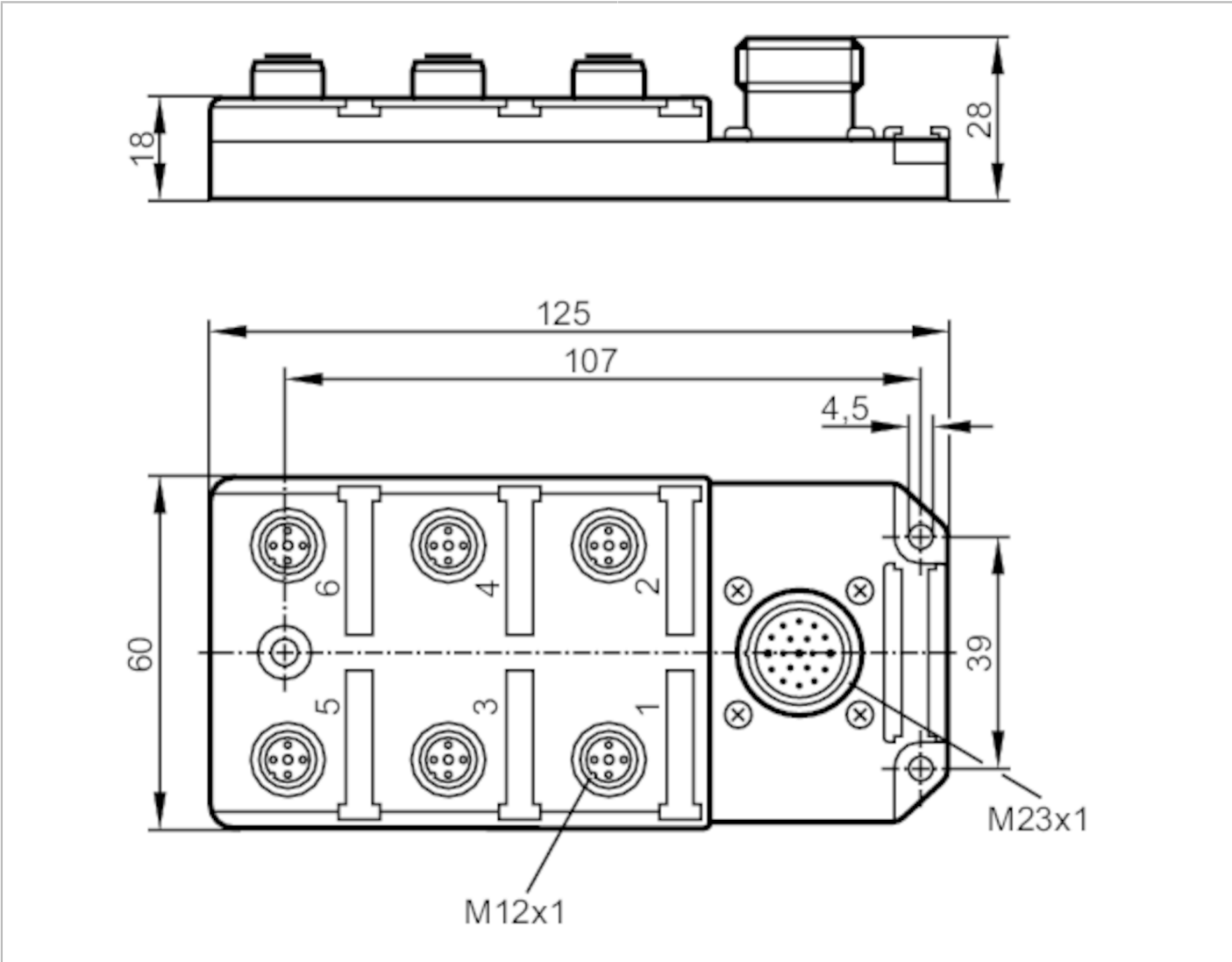

Application		
System		Free from silicone; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	10
Operating conditions		
Ambient temperature	[°C]	-15...80
Protection		IP 67

E11731



Wiring block


ZDO6H050MSS0000-00STAK190MSS

Mechanical data		
Dimensions	[mm]	28 x 60 x 125
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Number of ports splitter box		6
Connector type		M12

Remarks	
Pack quantity	1 pcs.

Electrical connection - Connection

Connector: 1 x M23; Moulded body: TPU (urethane); Contacts: gold-plated; Tightening torque: 0.5 Nm

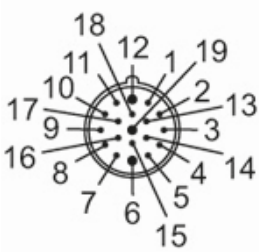

Connection

+	19	1 (1...6)	C
-	6	3 (1...6)	C
⊥	12	5 (1...6)	C
	15	4 (1)	C
	7	2 (1)	C
	5	4 (2)	C
	4	2 (2)	C
	16	4 (3)	C
	8	2 (3)	C
	3	4 (4)	C
	14	2 (4)	C
	17	4 (5)	C
	9	2 (5)	C
	2	4 (6)	C
	13	2 (6)	C

E11731



Wiring block

ZDO6H050MSS0000-00STAK190MSS

Electrical connection - slot

Connector: 6 x M12; coding: A; Moulded body: TPU (urethane); Contacts: gold-plated; Tightening torque: 0.5 Nm

