

E11732




Wiring block

ZDO8H050MSS0005H11

Article no longer available - archive entry

Alternative articles: EBC022
When selecting an alternative article and accessories please note that technical data may differ!

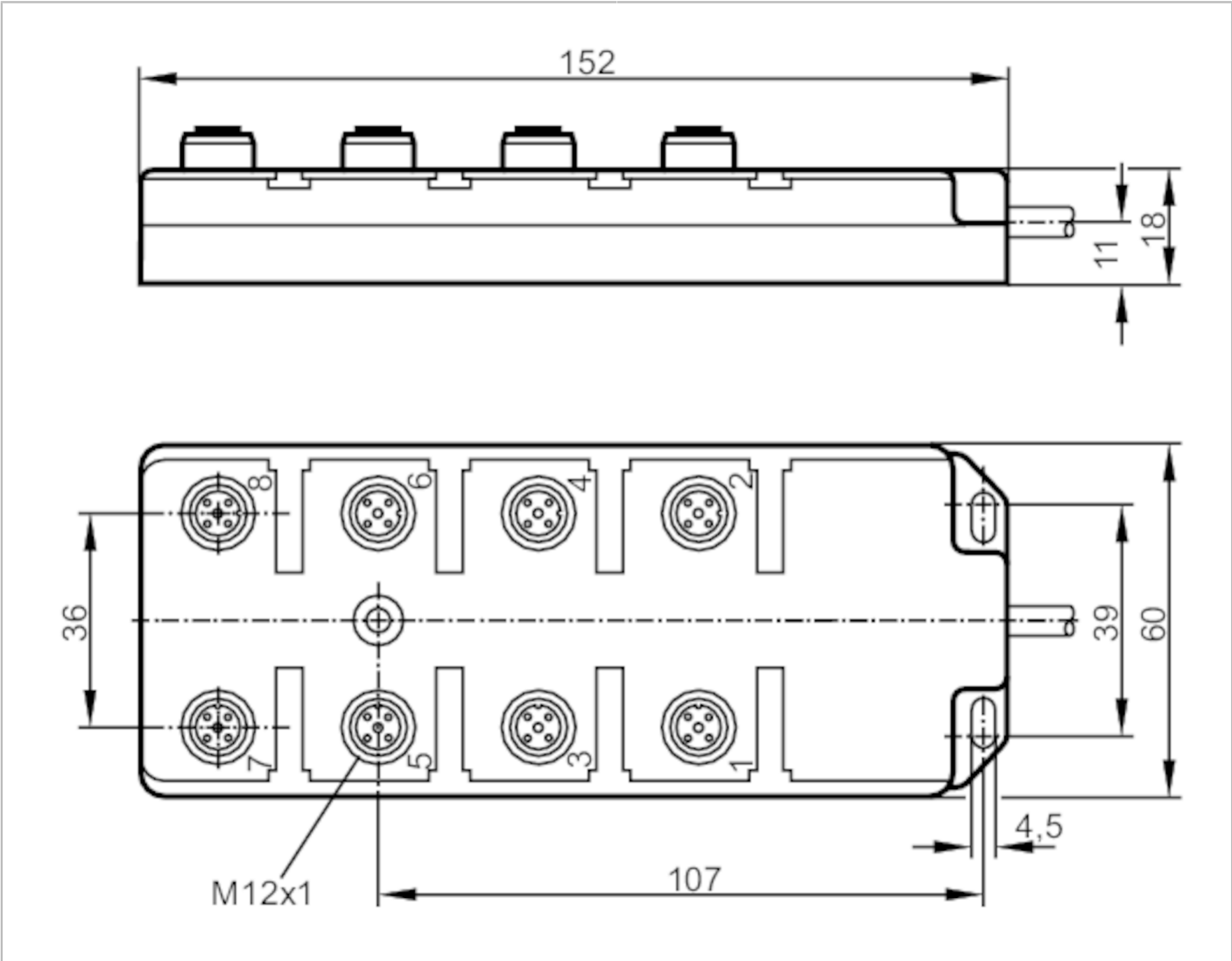

Application

System	Free from silicone; Halogen-free; gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12

Operating conditions

Ambient temperature	[°C]	-15...80
Protection		IP 67

E11732



Wiring block

ZDO8H050MSS0005H11

Mechanical data	
Material	TPU (urethane)
Molded-body material	TPU (urethane)
Number of ports splitter box	8
Connector type	M12
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 5 m, PUR, Halogen-free, black, Ø 11.6 mm; 16 x 0.5 mm ² (63 x Ø 0.1 mm) + 3 x 1.0 mm ² (127 x Ø 0.1 mm)	
Electrical connection - slot	
Connector: 8 x M12; coding: A; Moulded body: TPU (urethane); Contacts: gold-plated; Tightening torque: 0.5 Nm	

E11732



Wiring block

ZDO8H050MSS0005H11

Connection

<u>BN</u>	1 (1...8)	C
<u>BU</u>	3 (1...8)	C
<u>GN/YE</u>	5 (1...8)	C
<u>GY/PK</u>	2 (1)	C
<u>RD/BU</u>	2 (2)	C
<u>WH/GN</u>	2 (3)	C
<u>BN/GN</u>	2 (4)	C
<u>WH/YE</u>	2 (5)	C
<u>YE/BN</u>	2 (6)	C
<u>WH/GY</u>	2 (7)	C
<u>GY/BN</u>	2 (8)	C
<u>WH</u>	4 (1)	C
<u>GN</u>	4 (2)	C
<u>YE</u>	4 (3)	C
<u>GY</u>	4 (4)	C
<u>PK</u>	4 (5)	C
<u>RD</u>	4 (6)	C
<u>BK</u>	4 (7)	C
<u>VT</u>	4 (8)	C

	Core colors :
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
WH =	white
YE =	yellow