

E11735




Wiring block

ZDO4H055MSS0000-00STAK120MSS

Article no longer available - archive entry

Alternative articles: EBC002
When selecting an alternative article and accessories please note that technical data may differ!

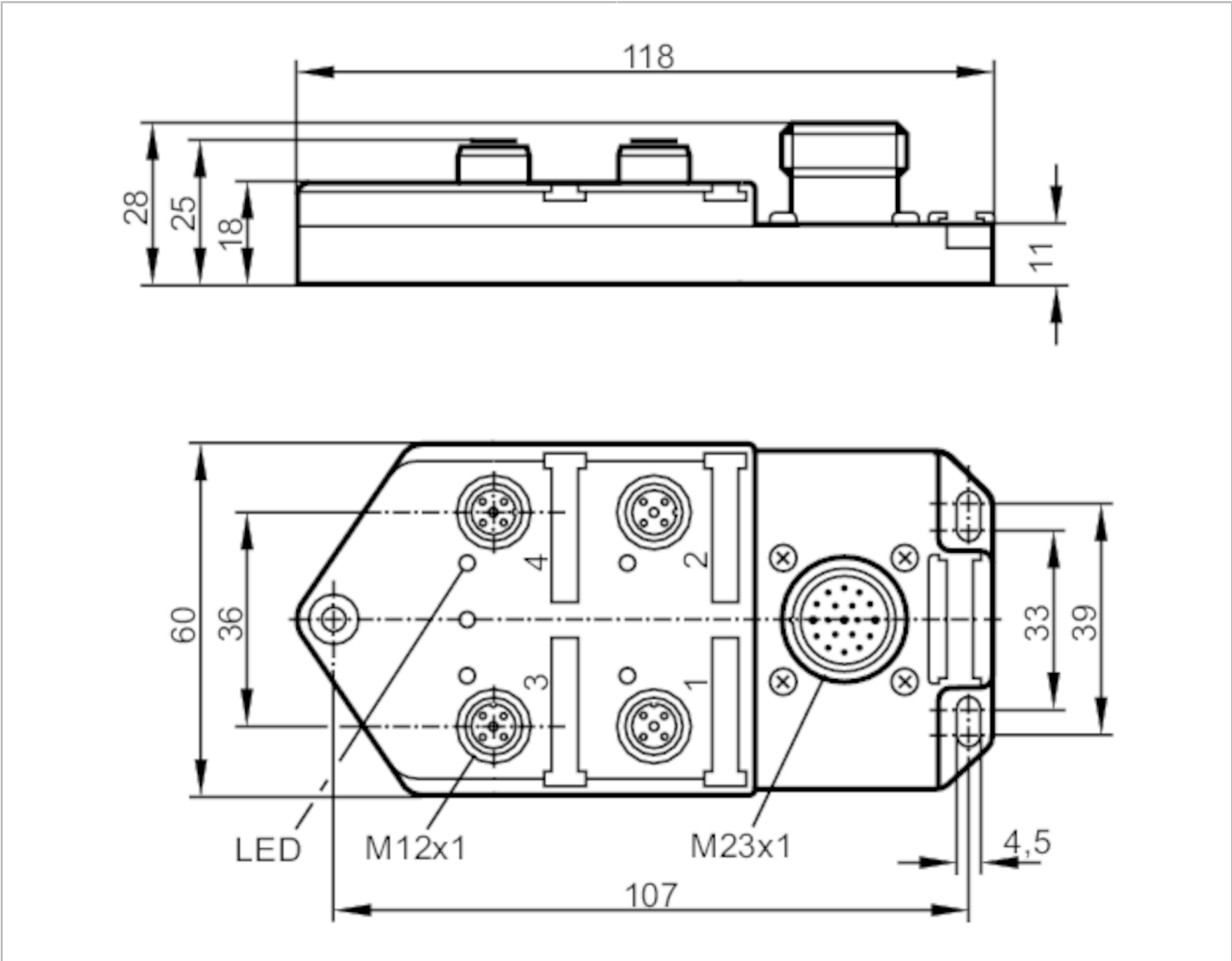

Application

System	Free from silicone; gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	10...30 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12

Operating conditions

Ambient temperature	[°C]	-15...80
Protection		IP 67

E11735



Wiring block

ZDO4H055MSS0000-00STAK120MSS

Mechanical data		
Dimensions	[mm]	28 x 60 x 118
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Number of ports splitter box		4
Connector type		M12

Displays / operating elements		
Display	Switching status	4 x LED, yellow
	Power	1 x LED, green


Remarks	
Pack quantity	1 pcs.

Electrical connection - Connection

Connector: 1 x M23; Moulded body: TPU (urethane); Contacts: gold-plated; Tightening torque: 0.5 Nm



Connection

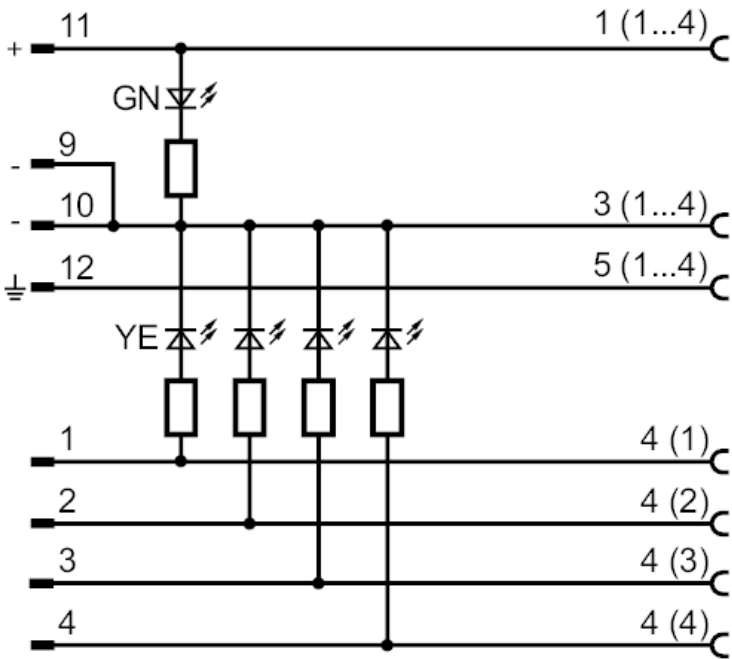

E11735



Wiring block

ZDO4H055MSS0000-00STAK120MSS

Electrical connection - slot

Connector: 4 x M12; coding: A; Moulded body: TPU (urethane); Contacts: gold-plated; Tightening torque: 0.5 Nm

