


E11742



Female cordset

ADOGK190MSS0005H19

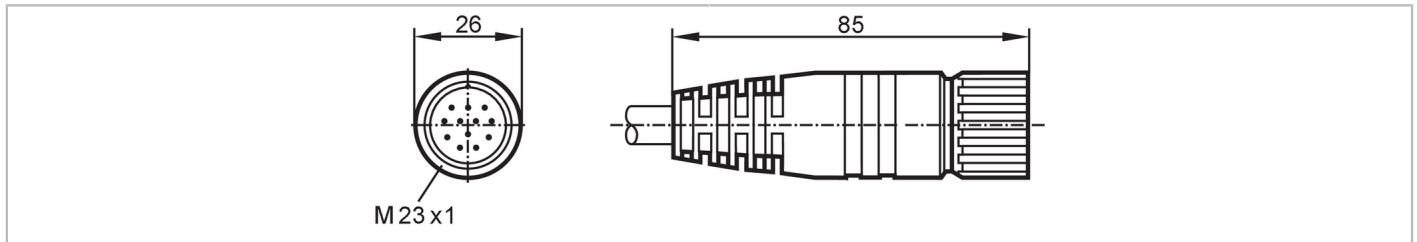


| Application | |
|-----------------------------|-------------------------|
| Special feature | Halogen-free |
| Application | Industrial applications |
| Electrical data | |
| Operating voltage [V] | < 63 AC/DC |
| Max. current load total [A] | 8 |
| Operating conditions | |
| Ambient temperature [°C] | -25...80 |
| Protection | IP 67 |
| Mechanical data | |
| Weight [g] | 1141 |
| Dimensions [mm] | 26 x 26 x 85 |
| Molded-body material | PUR |
| Material nut | brass, nickel-plated |
| Tightening torque [Nm] | 2 |
| Remarks | |
| Pack quantity | 1 pcs. |

Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 11.6 mm; 16 x 0.5 mm² (63 x Ø 0.1 mm) + 3 x 1.0 mm² (127 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M23, straight; Contacts: 19; Moulded body: PUR, black; Locking: brass, nickel-plated

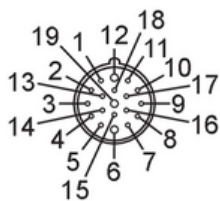

E11742



Female cordset

ADOGK190MSS0005H19

Connection

| | |
|----|-------|
| 1 | VT |
| 2 | RD |
| 3 | GY |
| 4 | RD/BU |
| 5 | GN |
| 6 | BU |
| 7 | GY/PK |
| 8 | WH/GN |
| 9 | WH/YE |
| 10 | WH/GY |
| 11 | BK |
| 12 | GN/YE |
| 13 | YE/BN |
| 14 | BN/GN |
| 15 | WH |
| 16 | YE |
| 17 | PK |
| 18 | GY/BN |
| 19 | BN |

| | |
|------|---------------|
| | Core colors : |
| BK = | black |
| BN = | brown |
| BU = | blue |
| GN = | green |
| GY = | grey |
| PK = | pink |
| RD = | red |
| VT = | lilac |
| WH = | white |
| YE = | yellow |