




Y connection cable

YDOGH040MSS0001H04STGH050MSS

Article no longer available - archive entry

Alternative articles: EVC431
When selecting an alternative article and accessories please note that technical data may differ!

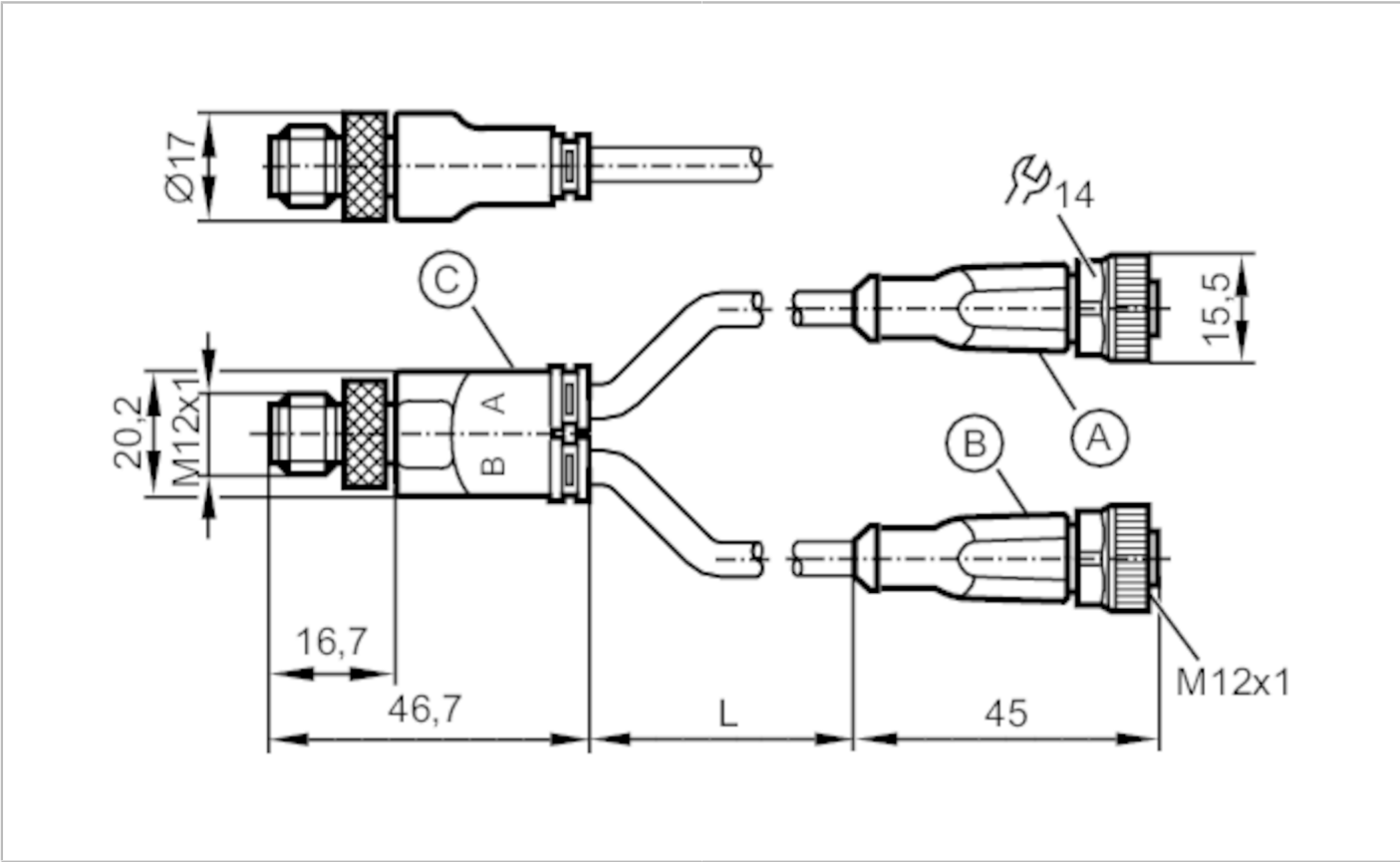

Application		
System		Free from silicone; Halogen-free; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Weight	[g]	111.5
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Sealing material		plastics
Number of ports splitter box		2
Remarks		
Pack quantity		1 pcs.



Y connection cable


YDOGH040MSS0001H04STGH050MSS

Electrical connection

Cable: 1 m, PUR, Halogen-free, black, Ø 4.9 mm; 5 x 0.34 mm² (42 x Ø 0.1 mm)


Electrical connection - Socket

Connector: 2 x M12, straight; coding: A; Moulded body: TPU (urethane), black transparent; Locking: brass, nickel-plated; sealing: plastics; Contacts: gold-plated

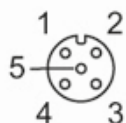

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane), black; Locking: brass, nickel-plated; Contacts: gold-plated

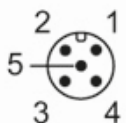

Connection

