


# E11807



## Female cordset

ADOGH080MSS0005H08

For 8-wire cordsets the core colors are not standardized.  
Please note the wiring of the sensor and the cordsets (see data sheet).

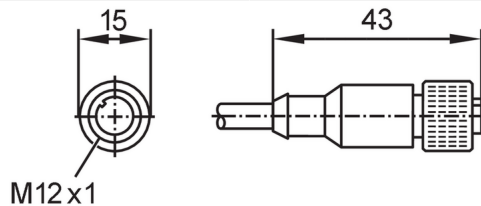

Application	
Application	Industrial applications
Electrical data	
Operating voltage [V]	< 30 AC / < 36 DC
Operating conditions	
Ambient temperature [°C]	-25...80
Protection	IP 68
Mechanical data	
Weight [g]	313.7
Dimensions [mm]	15 x 15 x 43
Material	PUR
Molded-body material	PUR
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

**Electrical connection**  
Cable: 5 m, PUR, black, Ø 6.2 mm; 8 x 0.25 mm<sup>2</sup>

**Electrical connection - Socket**  
Connector: 1 x M12, straight; coding: A; Contacts: 8; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm




# E11807



## Female cordset

ADOGH080MSS0005H08

### Connection

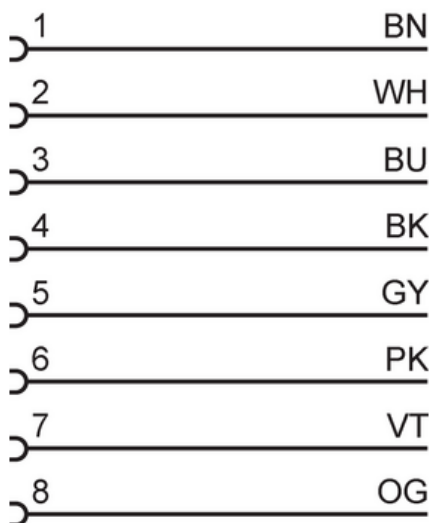

Colors to DIN EN 60947-5-2

Core colors :

BK =	black
BN =	brown
BU =	blue
GY =	grey
PK =	pink
OG =	orange
VT =	lilac
WH =	white