


E11843



Female cordset

ADOAH050MSN0025A05

Article no longer available - archive entry

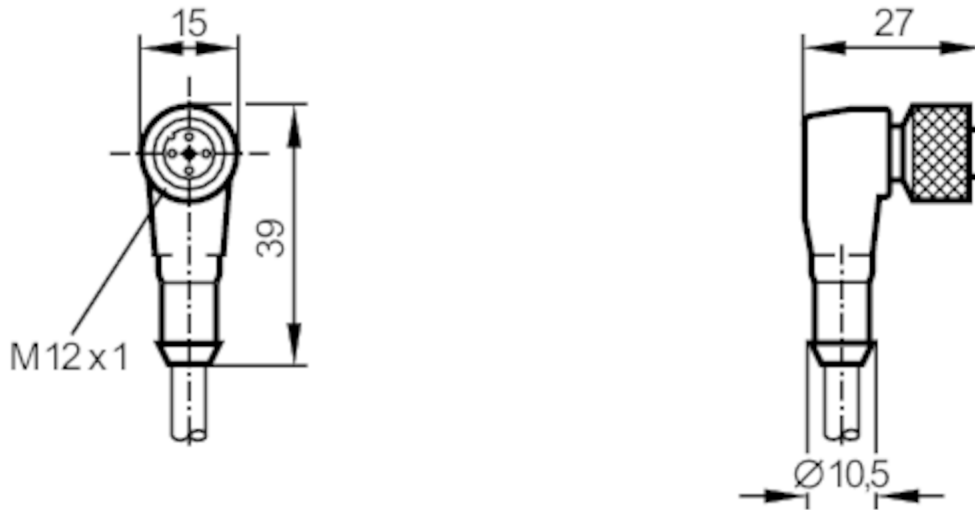

Application

Application Ex zone 1

Electrical data

Operating voltage [V] 10...30 DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Safety classification

Max. internal capacitance [nF] 1.9

Max. internal inductance [µH] 14.75

Mechanical data

Dimensions [mm] 27 x 15 x 39

Material TPU (urethane)

Material nut brass, nickel-plated

Remarks

Remarks When using sockets in hazardous areas (ATEX) there are special requirements regarding wiring. The requirements of the applicable installation regulations must be absolutely adhered to by the user on his own responsibility.

Pack quantity 1 pcs.

Electrical connection

Cable: 25 m, PUR / PVC, blue, Ø 6 mm; 5 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket


Connector: 1 x M12, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated

E11843



Female cordset

ADOAH050MSN0025A05

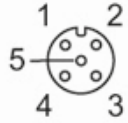

Connection

1	BN
2	WH
3	BU
4	BK
5	GY

Core colors :

BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white

Article no longer available - archive entry