


E11844



Female cordset

ADOAH050MSN0050A05

Article no longer available - archive entry

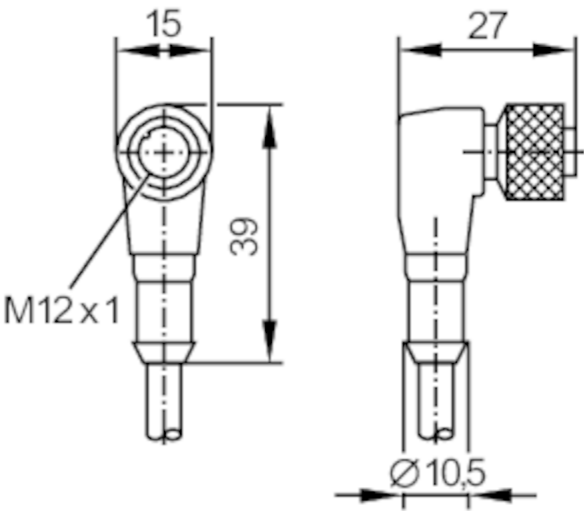

Application	
Application	Ex zone 1
Electrical data	
Operating voltage [V]	10...30 DC
Operating conditions	
Ambient temperature [°C]	-25...90
Protection	IP 67
Safety classification	
Max. internal capacitance [nF]	3.8
Max. internal inductance [µH]	29.5
Mechanical data	
Dimensions [mm]	27 x 15 x 39
Material	TPU (urethane)
Molded-body material	TPU (urethane)
Material nut	brass, nickel-plated
Remarks	
Remarks	When using sockets in hazardous areas (ATEX) there are special requirements regarding wiring. The requirements of the applicable installation regulations must be absolutely adhered to by the user on his own responsibility.
Pack quantity	1 pcs.

E11844



Female cordset


ADOAH050MSN0050A05

Electrical connection

Cable: 50 m, PUR / PVC, blue, Ø 6 mm; 5 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

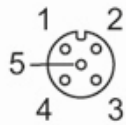

Connection

1	BN
2	WH
3	BU
4	BK
5	GY

	Core colors :
BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white