


# E11856



## Female cordset

ADOGH080MSS0015K08

For 8-wire cordsets the core colors are not standardized.  
Please note the wiring of the sensor and the cordsets (see data sheet).

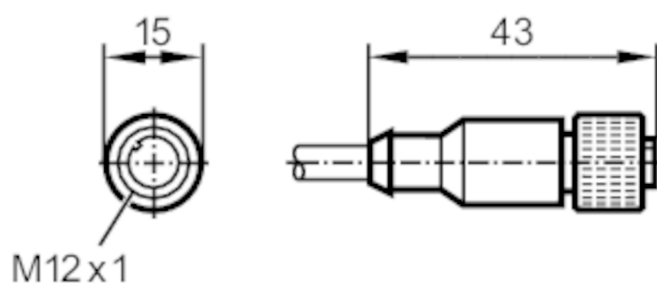

Application		
System		screened cable
Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC
Protection class		III
Operating conditions		
Ambient temperature	[°C]	-25...80
Protection		IP 67
Mechanical data		
Weight	[g]	976.3
Dimensions	[mm]	15 x 15 x 43
Material		PUR
Molded-body material		PUR
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

# E11856



## Female cordset

ADOGH080MSS0015K08

### Electrical connection


Cable: 15 m, PUR, black, Ø 6.6 mm, screened; 8 x 0.25 mm<sup>2</sup> (14 x Ø 0.15 mm )

### Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm;  
Shielded connection cable: shield connected



### Connection

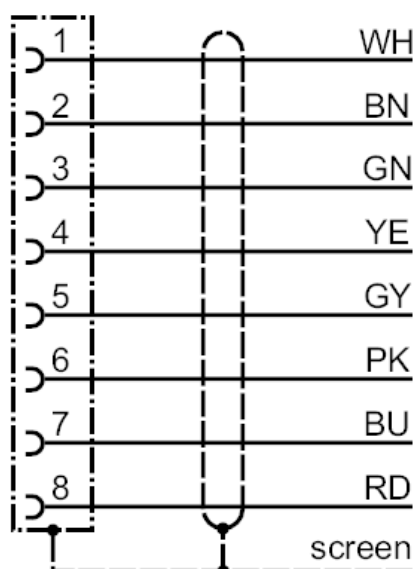

#### Colors to DIN 47100

##### Core colors :

BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
WH =	white
YE =	yellow
screen =	screen