

E11903




Male cordsets

ASTAH050MSS0002H05

Article no longer available - archive entry

Alternative articles: EVC095

When selecting an alternative article and accessories please note that technical data may differ!

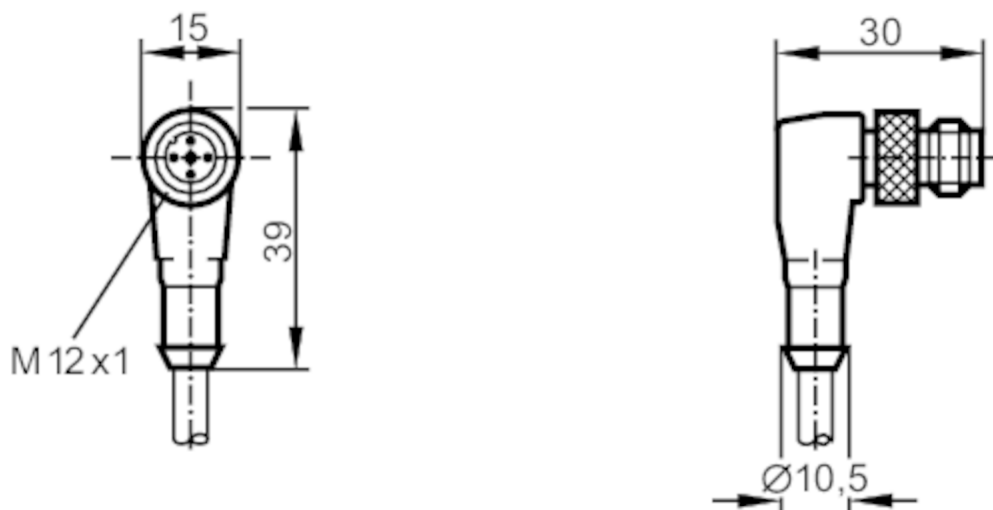

Application

System	Free from silicone; Halogen-free; gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	39 x 15 x 30
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E11903



Male cordsets


ASTAH050MSS0002H05

Electrical connection

Cable: 2 m, PUR, Halogen-free, black, Ø 5 mm; 5 x 0.34 mm² (43 x Ø 0.1 mm)

Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.5 Nm

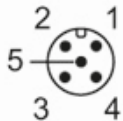

Connection

1	BN
2	WH
3	BU
4	BK
5	GY

	Core colors :
BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white