

E11924




Female cordset

ADOAH040VAS0040E04

Article no longer available - archive entry

Alternative articles: EVT066

When selecting an alternative article and accessories please note that technical data may differ!

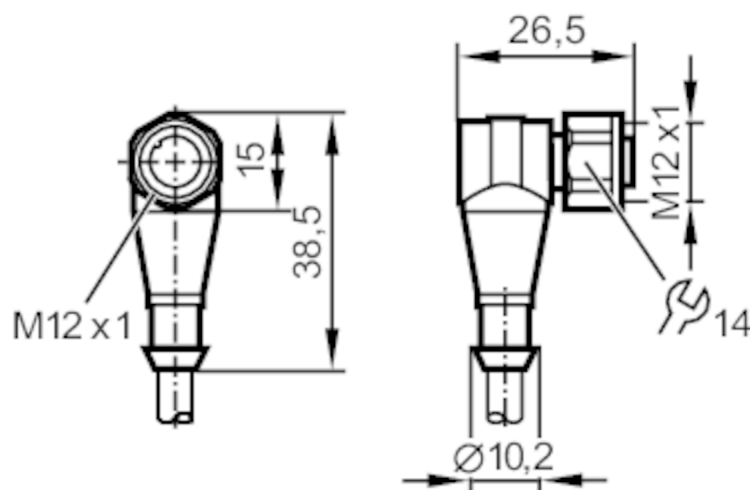

Application

System	Free from silicone; gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...100
Protection		IP 68; IP 69K

Mechanical data

Dimensions	[mm]	26.5 x 15 x 38.5
Material		PVC
Molded-body material		PVC
Material nut		stainless steel (1.4404 / 316L)

Remarks

Pack quantity	1 pcs.
---------------	--------

E11924



Female cordset

ADOAH040VAS0040E04

Electrical connection


Cable: 40 m, PVC, orange, Ø 5.3 mm; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



Connection

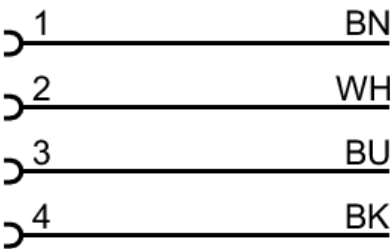

	Core colors :
BK =	black
BN =	brown
BU =	blue
WH =	white