


E11002



Connection cable

VSTGH030MSS0005I03DOGF030MSS

Article no longer available - archive entry

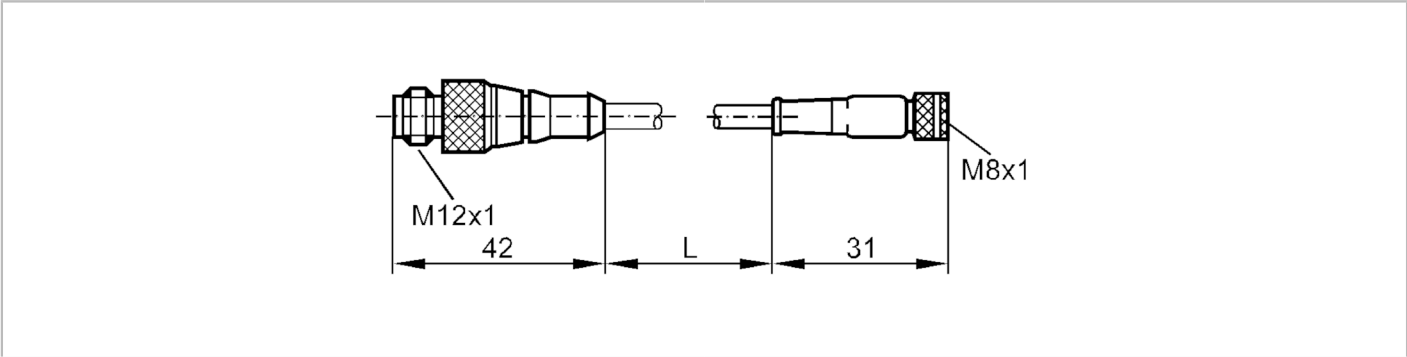

Application

System	Halogen-free
--------	--------------

Electrical data

Operating voltage	[V]	10...30 DC
Protection class		III

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data


Material	TPU (urethane)
Molded-body material	TPU (urethane)
Material nut	brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

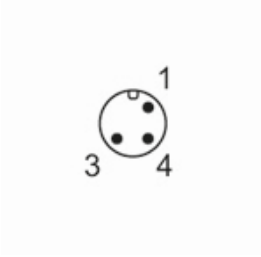

E11002



Connection cable

VSTGH030MSS0005I03DOGF030MSS

Electrical connection

Cable: 5 m, PUR, Halogen-free; cross-linked; 3 x 0.34 mm²

Connection



Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

