


E11005



Connection cable

VSTGH030MSS0005I03DOAF030MSS

Article no longer available - archive entry

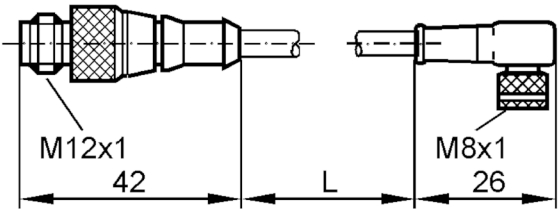

Application		
System		Halogen-free
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		III
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection - plug		

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



E11005




Connection cable

VSTGH030MSS0005I03DOAF030MSS

Electrical connection

Cable: 5 m, PUR, Halogen-free; cross-linked; 3 x 0.34 mm²

Connection

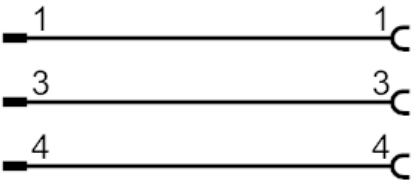

Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

