


E11013



Connection cable

VSTGH050MSS0005I03VDAA041--S

Article no longer available - archive entry

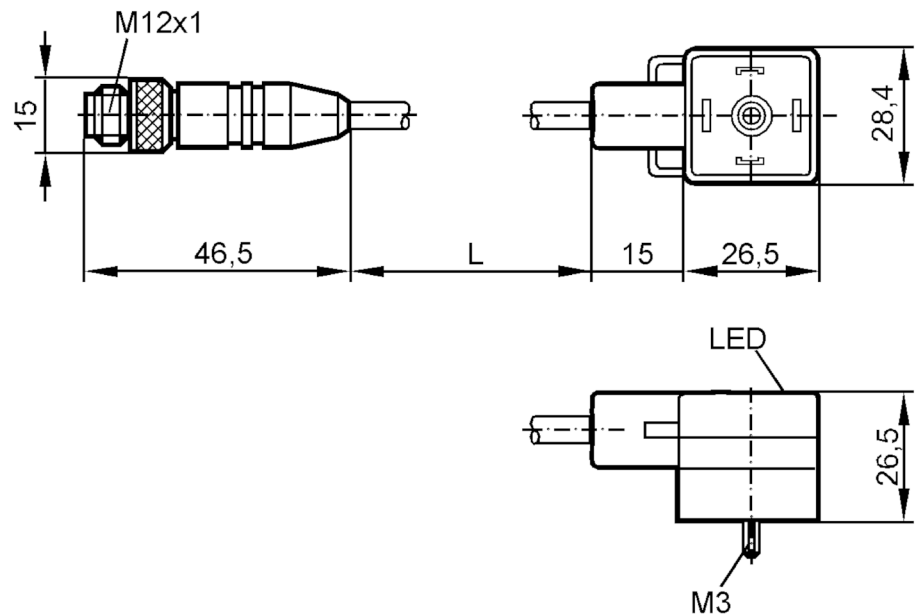

Application

System

Halogen-free

Electrical data

Operating voltage

[V]

< 24 AC/DC

Overvoltage protection

yes; (VDR)

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Dimensions

[mm]

15 x 15 x 46.5

Material

TPU (urethane)

Molded-body material

TPU (urethane)

Material nut

brass, nickel-plated

Accessories

Items supplied

screw

panel for labelling

Remarks

Pack quantity

1 pcs.

E11013



Connection cable

VSTGH050MSS0005I03VDAA041--S

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Electrical connection

Cable: 5 m, PUR, Halogen-free; cross-linked; 3 x 0.5 mm²

Connection



Electrical connection - Socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated

