


E11035



Mounting adapter for capacitive sensors

MOUNTING ADAPTER M30 POM

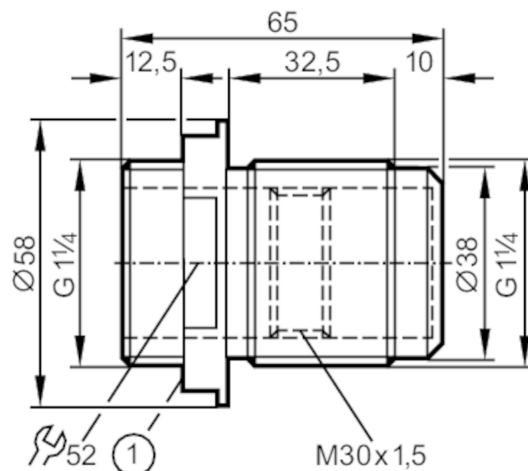

1 O-ring 44 x 2 mm

Application

Medium temperature	[°C]	-25...100
Medium temperature short time	[°C]	-25...110
Pressure rating	[bar]	8

Mechanical data

Weight	[g]	79.2
Dimensions	[mm]	G 1 1/4 / L = 65
Thread designation		G 1 1/4
Material		Adapter: POM; Gasket: EPDM
Sensor connection		threaded connection M30 x 1,5 Internal thread
Process connection		threaded connection G 1 1/4 external thread

Remarks

Pack quantity	1 pcs.
---------------	--------