

E11041




Connection cable

VDOAH043MSS00,3I04STGH040MSS

Article no longer available - archive entry

Alternative articles: EVC020

When selecting an alternative article and accessories please note that technical data may differ!

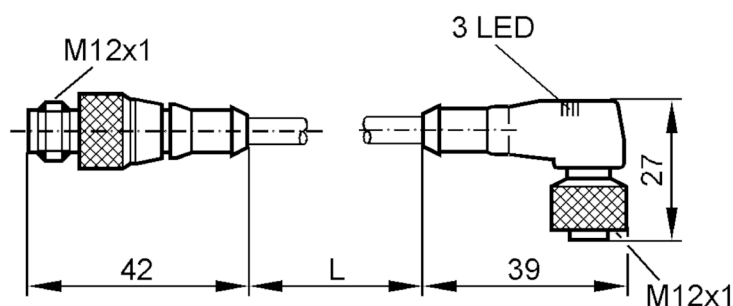

Application

System

Halogen-free

Electrical data

Operating voltage

[V]

10...30 DC

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Material

TPU (urethane)

Molded-body material

TPU (urethane)

Material nut

brass, nickel-plated

Displays / operating elements

Display

Switching status

2 x LED, yellow

Power

1 x LED, green

Remarks

Pack quantity

1 pcs.

E11041



Connection cable

VDOAH043MSS00,3I04STGH040MSS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Electrical connection

Cable: 0.3 m, PUR, Halogen-free; cross-linked; 4 x 0.34 mm² (19 x Ø 0.15 mm)

Connection



Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

