


E11046



Female cordset

ADOAH040ZDS0010E04

Article no longer available - archive entry

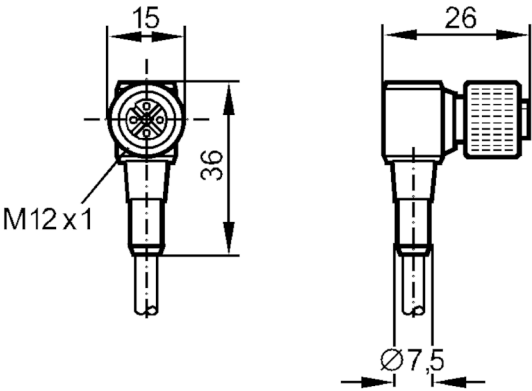

Electrical data		
Operating voltage	[V]	< 250 AC/DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Material		PUR
Molded-body material		PUR
Material nut		diecast zinc
Remarks		
Pack quantity		1 pcs.

Electrical connection

Cable: 10 m, PVC, black, Ø 4.5 mm; 4 x 0.34 mm²

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: diecast zinc




E11046



Female cordset

ADOAH040ZDS0010E04

Connection

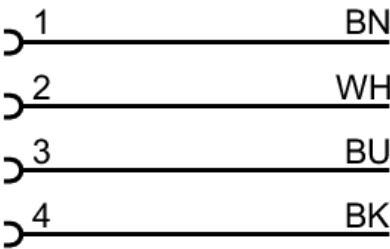

BK = Core colors :
BN = black
BU = brown
WH = blue
BK = white