

E11059




Female cordset

ADOAG030--S0002A03

Article no longer available - archive entry

Alternative articles: E10197
When selecting an alternative article and accessories please note that technical data may differ!

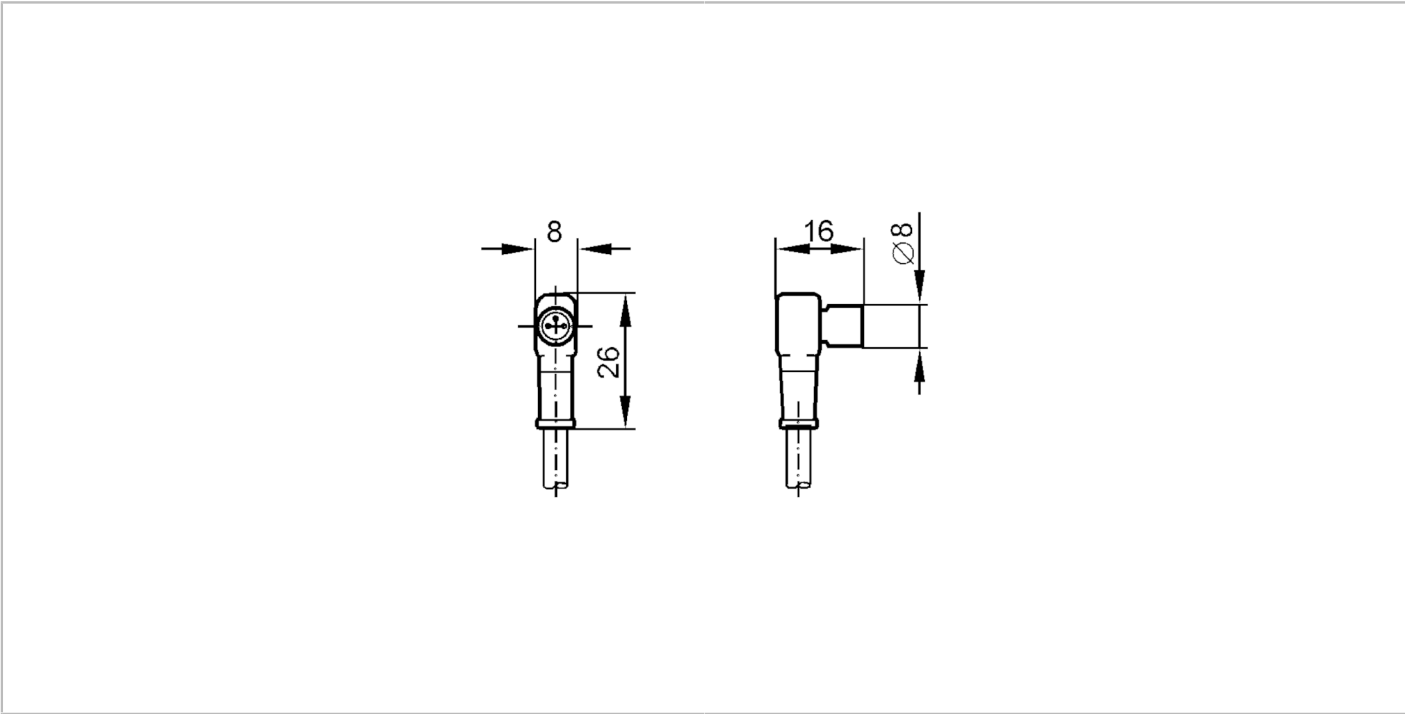

Electrical data		
Operating voltage	[V]	< 60 AC / < 75 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 65
Mechanical data		
Dimensions	[mm]	26 x 8 x 16
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Remarks		
Pack quantity		1 pcs.

E11059



Female cordset

ADOAG030--S0002A03


Electrical connection

Cable: 2 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)


Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: TPU (urethane); Locking: Snap-in

Connector: 1 x M8, angled; coding: A; Moulded body: TPU (urethane); Locking: Snap-in

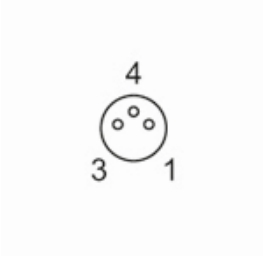

Connection

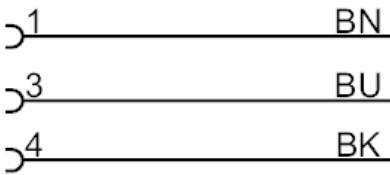

BN = Core colors : brown
BK = black
BU = blue