

E11062




Connection cable

VDOAH043MSS00,3H04STGH040MSS

Article no longer available - archive entry

Alternative articles: EVC020
When selecting an alternative article and accessories please note that technical data may differ!

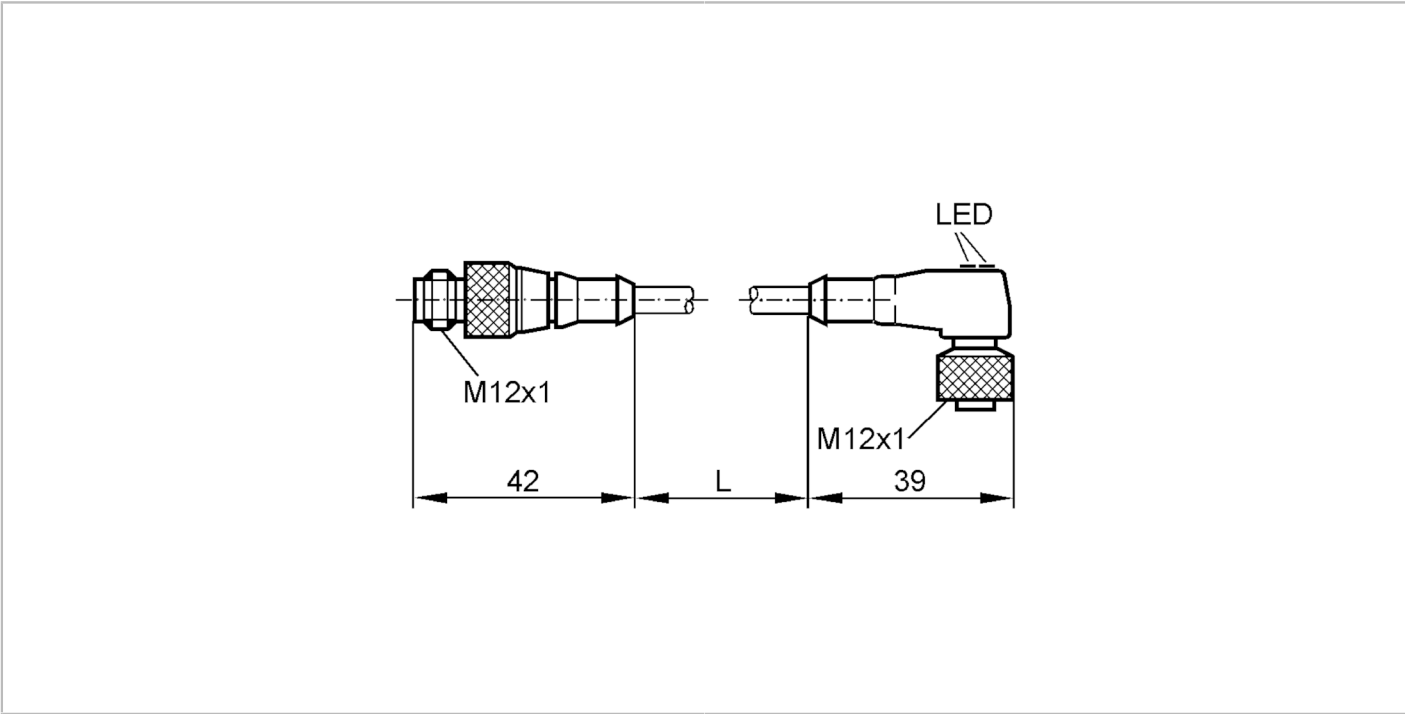

Application		
System		Halogen-free
Electrical data		
Operating voltage [V]		10...30 DC
Operating conditions		
Ambient temperature [°C]		-25...90
Protection		IP 67
Mechanical data		
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Displays / operating elements		
Display	Switching status	2 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E11062



Connection cable

VDOAH043MSS00,3H04STGH040MSS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, Ø 4.7 mm; 4 x 0.34 mm² (43 x Ø 0.1 mm)

Connection

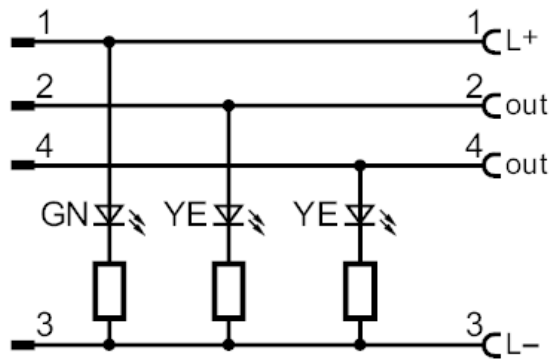

Core colors :
BK = black
BN = brown
BU = blue
WH = white

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

