


E11063



Connection cable

VDOAH043MSS00,6H04STGH040MSS

Article no longer available - archive entry

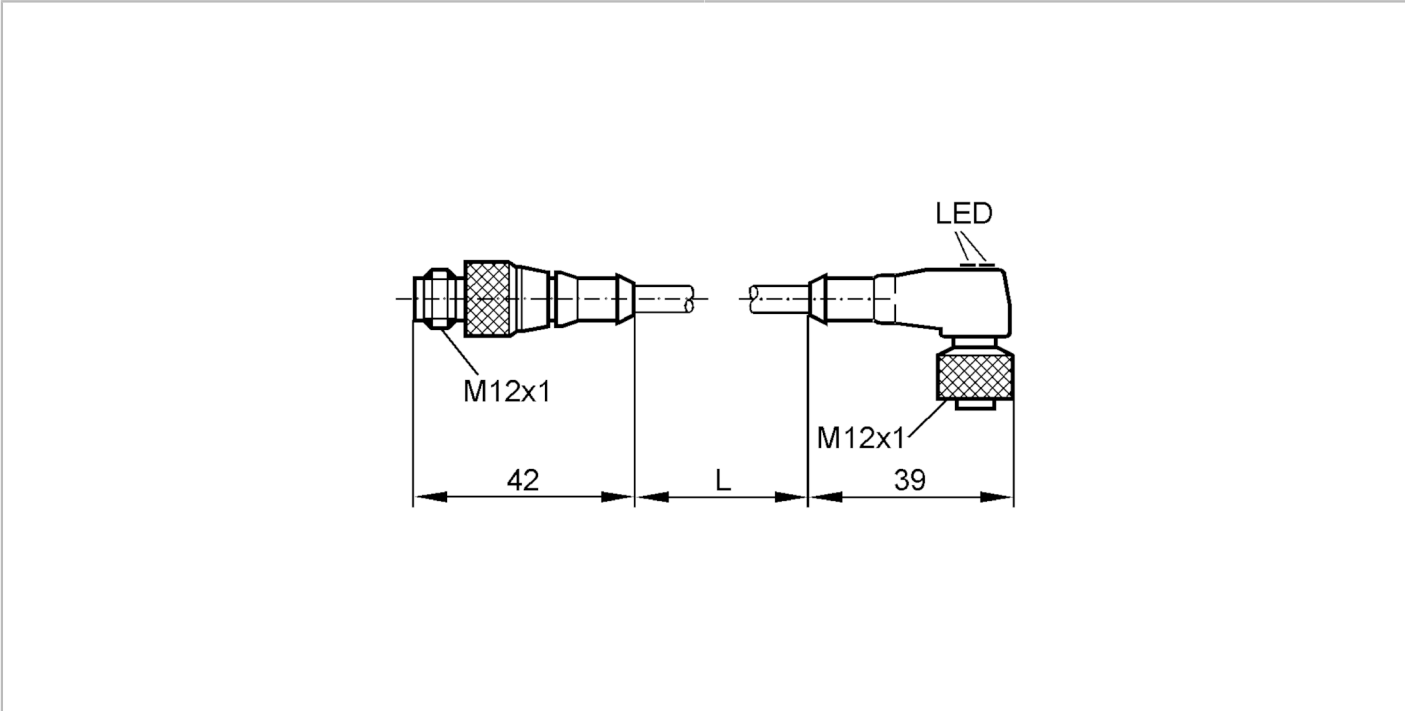

Application		
System		Halogen-free
Electrical data		
Operating voltage [V]		10...30 DC
Operating conditions		
Ambient temperature [°C]		-25...90
Protection		IP 67
Mechanical data		
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Displays / operating elements		
Display	Switching status	2 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E11063



Connection cable

VDOAH043MSS00,6H04STGH040MSS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Electrical connection

Cable: 0.6 m, PUR, Halogen-free, black, Ø 4.7 mm; 4 x 0.34 mm²

Connection

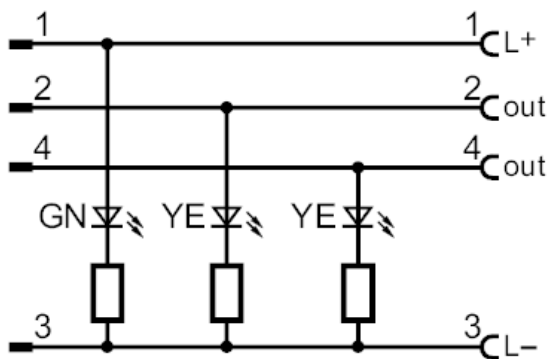

Core colors :
BK = black
BN = brown
BU = blue
WH = white

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

