


E11066



Connection cable

VDOAH043MSS0002H04STAH040MSS

Article no longer available - archive entry

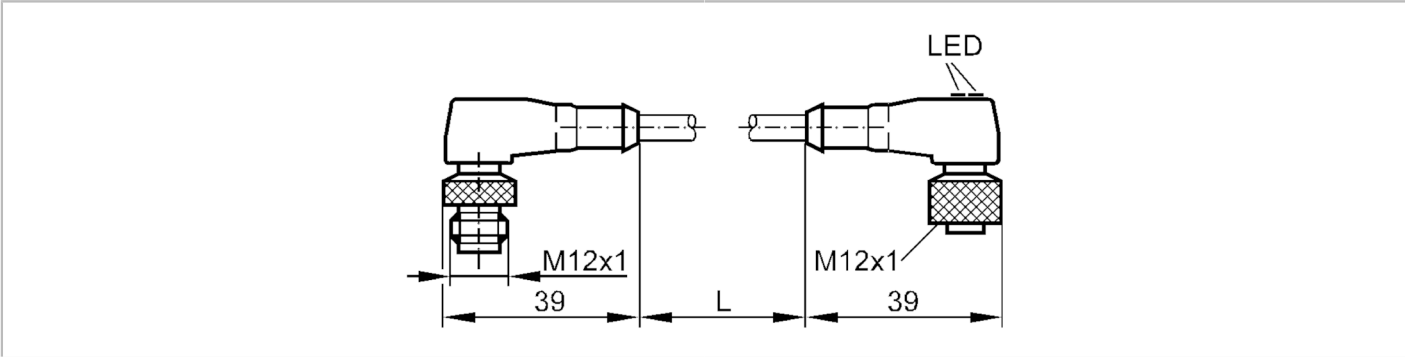

Application

System	Halogen-free
--------	--------------

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Material	TPU (urethane)
----------	----------------

Molded-body material	TPU (urethane)
----------------------	----------------

Material nut	brass, nickel-plated
--------------	----------------------

Displays / operating elements

Display	Switching status	2 x LED, yellow
	Power	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 2 m, PUR, Halogen-free, black, Ø 4.7 mm; 4 x 0.34 mm²

Electrical connection - plug



E11066




Connection cable

VDOAH043MSS0002H04STAH040MSS

Electrical connection

Connection

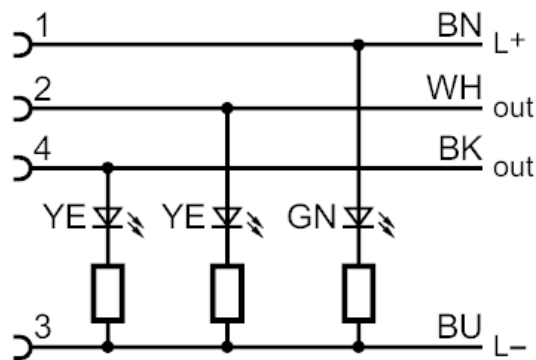

Core colors :
BK = black
BN = brown
BU = blue
WH = white

Electrical connection - Socket



Electrical connection - Socket

Connector: 1 x M12, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated

Electrical connection - plug

Connector: 1 x M12, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated