


# E11067



## Female receptacle

EDOGH040ZDS00,5E04 (PG9)

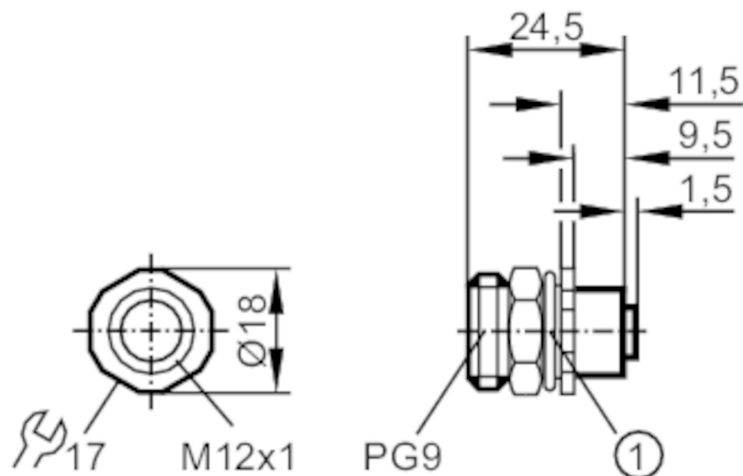

1 O-ring



### Electrical data

|                         |     |             |
|-------------------------|-----|-------------|
| Operating voltage       | [V] | < 250 AC/DC |
| Max. current load total | [A] | 4           |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...85 |
| Protection          |      | IP 68    |

### Mechanical data

|                      |     |              |
|----------------------|-----|--------------|
| Weight               | [g] | 22.8         |
| Mounting thread      |     | PG 9         |
| Material             |     | diecast zinc |
| Molded-body material |     | diecast zinc |

### Accessories

|                |  |              |
|----------------|--|--------------|
| Items supplied |  | Nut: 1 x PG9 |
|----------------|--|--------------|

### Remarks

|               |  |        |
|---------------|--|--------|
| Pack quantity |  | 1 pcs. |
|---------------|--|--------|

E11067



Female receptacle


EDOGH040ZDS00,5E04 (PG9)

Electrical connection


Cable: 0.5 m, PVC; 4 x 0.25 mm²

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: diecast zinc

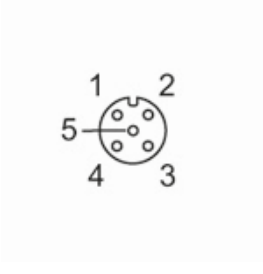

Connection

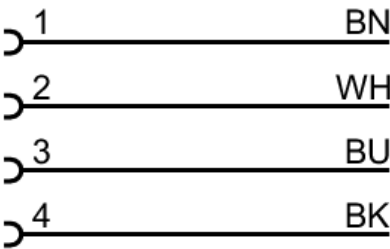

BK = Core colors :  
BN = black  
BU = brown  
WH = blue  
white