


E11069



Y connection cable

YDOAH042MSS0001I04STGH040MSS

Article no longer available - archive entry

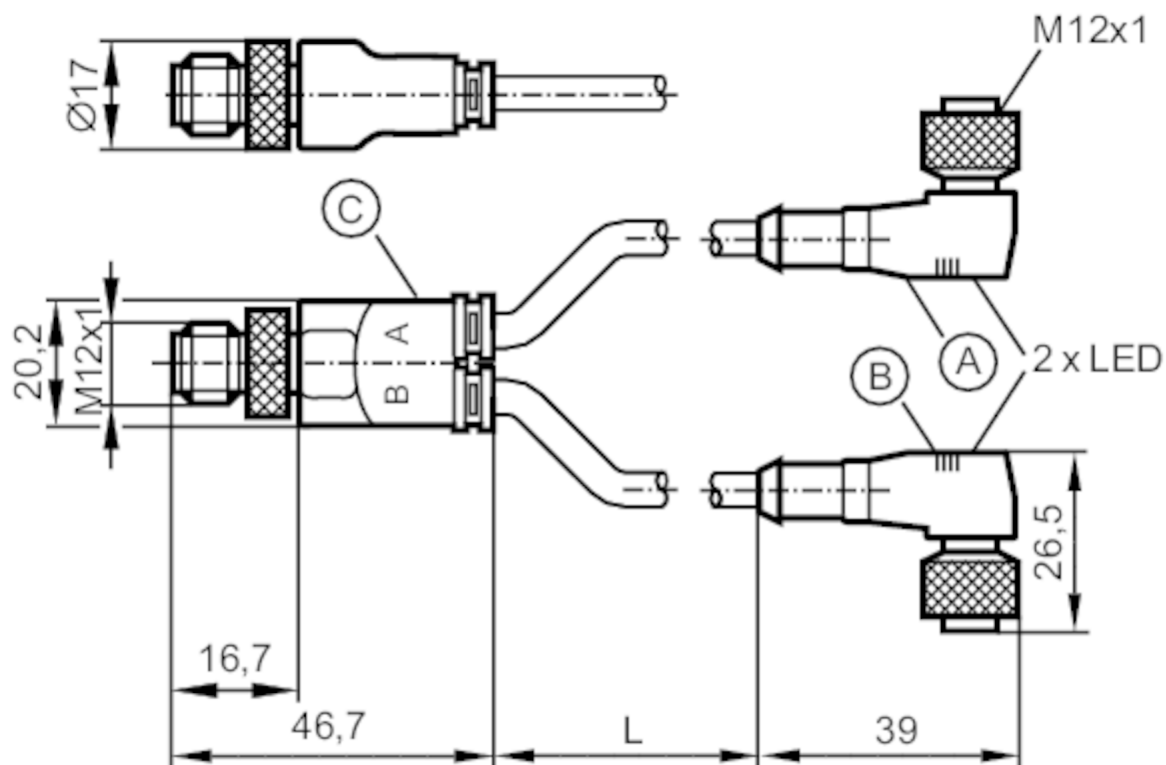

Application

System	Halogen-free
--------	--------------

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Dimensions	[mm]	17 x 20.2 x 46.7
------------	------	------------------

Material	TPU (urethane)
----------	----------------

Molded-body material	TPU (urethane)
----------------------	----------------

Material nut	brass, nickel-plated
--------------	----------------------

Number of ports splitter box	2
------------------------------	---

Displays / operating elements

Display	Switching status	1 x LED, red
	Power	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------



Y connection cable

YDOAH042MSS0001I04STGH040MSS

Electrical connection

Cable: 1 m, PUR, Halogen-free, black, Ø 4.3 mm; 3 x 0.34 mm² (43 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 2 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Connection

