




Female cordset

ADOAF030VAS0005E03

Article no longer available - archive entry

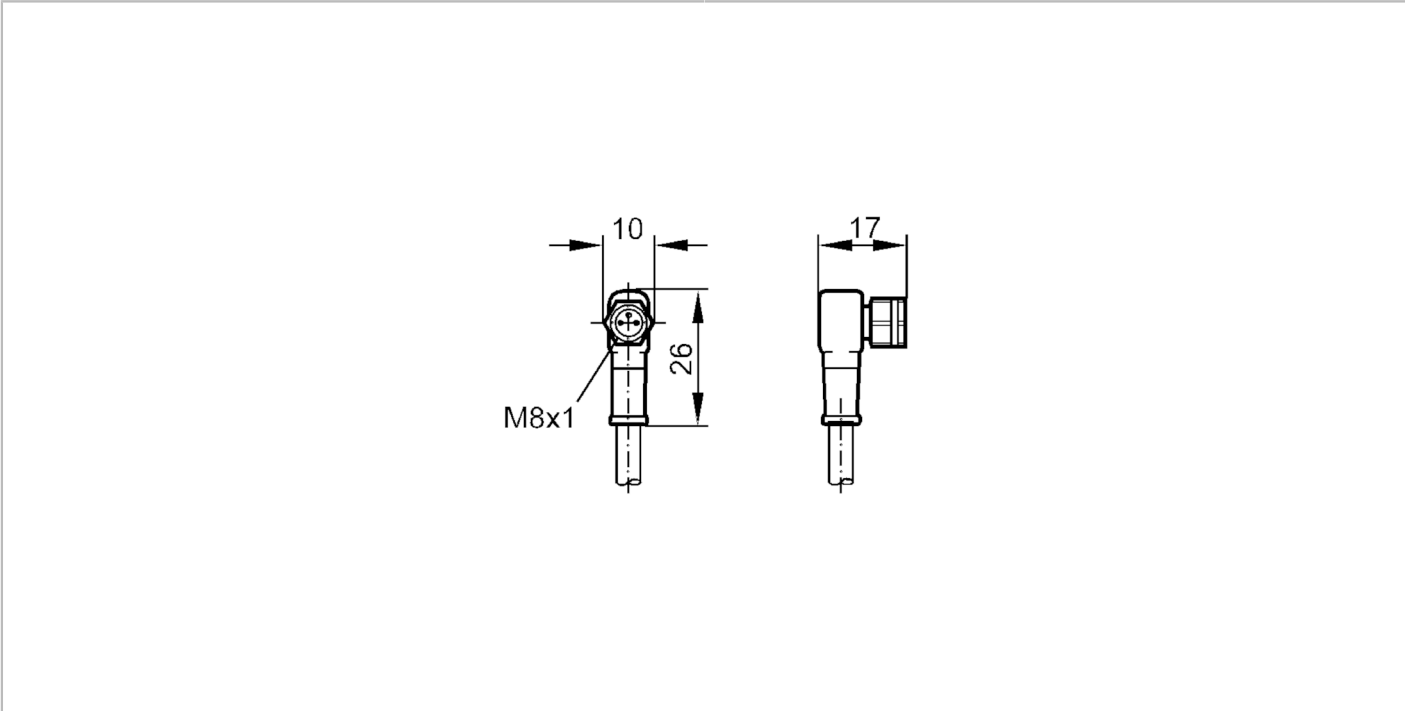

Electrical data		
Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III


Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data		
Dimensions	[mm]	17 x 10 x 26
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		stainless steel (1.4305 / 303)

Remarks		
Pack quantity		1 pcs.

Electrical connection		
Cable: 5 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)		

Electrical connection - Socket		
Connector: 1 x M8, angled; coding: A; Moulded body: TPU (urethane); Locking: stainless steel (1.4305 / 303)		

 


E11089



Female cordset

ADOAF030VAS0005E03

Connection

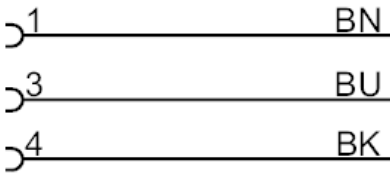

BN =	Core colors :	brown
BK =		black
BU =		blue