

E11095




Female cordset

ADOGF030VAS0005E03

Article no longer available - archive entry

Alternative articles: E11495
When selecting an alternative article and accessories please note that technical data may differ!

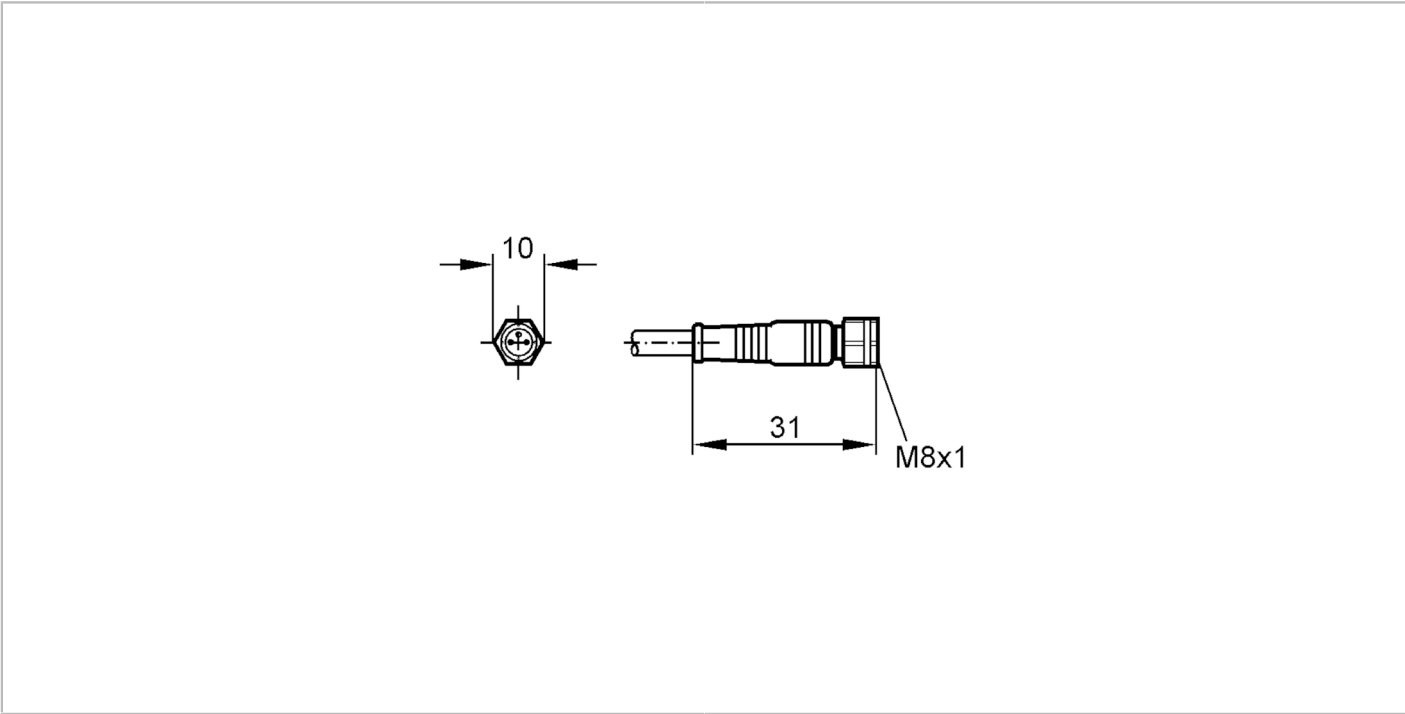

Electrical data		
Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67; (if screwed on)
Mechanical data		
Dimensions	[mm]	10 x 10 x 31
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		stainless steel (1.4305 / 303)
Remarks		
Pack quantity		1 pcs.

E11095



Female cordset

ADOGF030VAS0005E03

Electrical connection


Cable: 5 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU (urethane); Locking: stainless steel (1.4305 / 303)



Connection

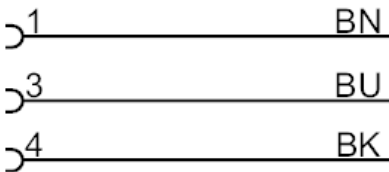

BN =	Core colors :
BK =	brown
BU =	black
	blue