




Female cordset

ADOGF030VAS0020E03

Article no longer available - archive entry

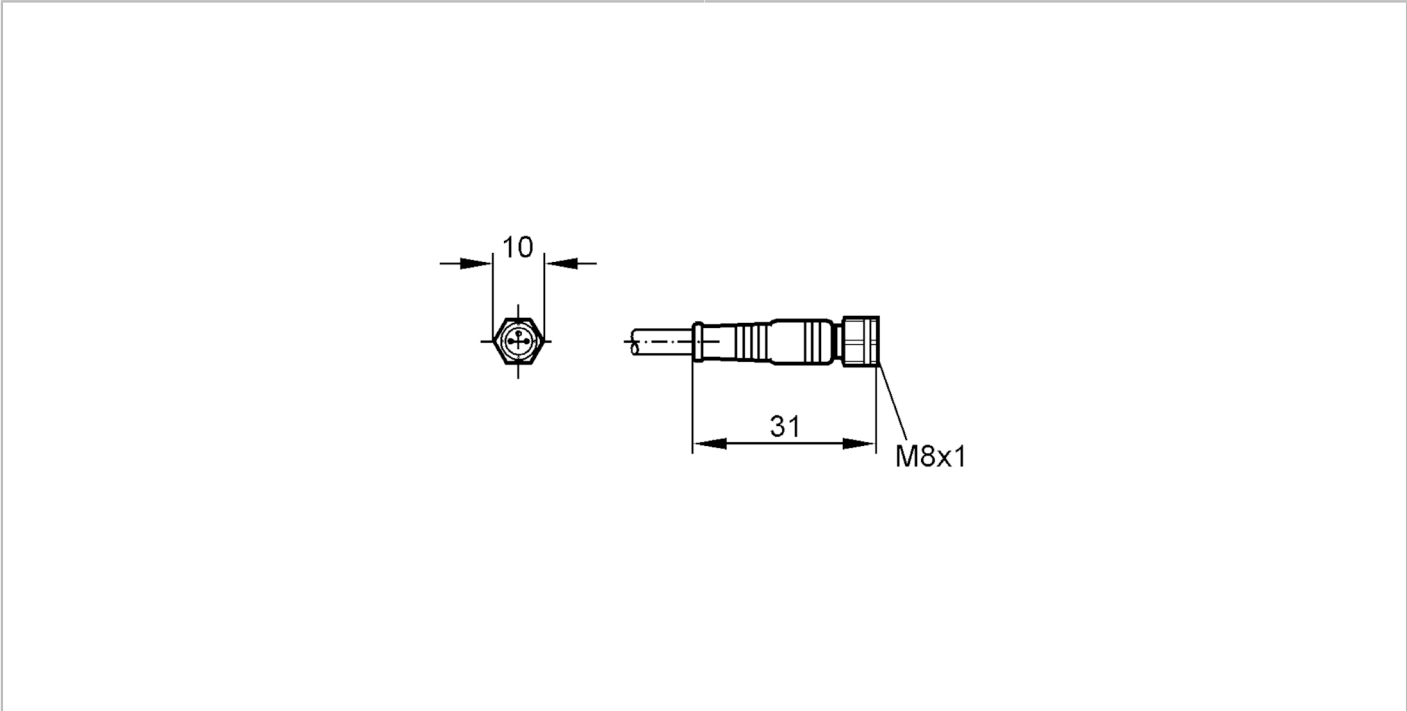

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67; (if screwed on)

Mechanical data

Dimensions	[mm]	10 x 10 x 31
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		stainless steel (1.4305 / 303)

Remarks


Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

Cable: 20 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU (urethane); Locking: stainless steel (1.4305 / 303)

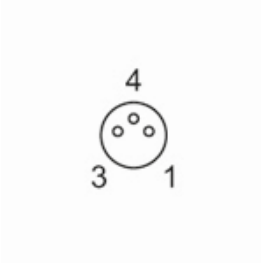

E11097



Female cordset

ADOGF030VAS0020E03

Connection



BN =	Core colors :	brown
BK =		black
BU =		blue