

E11105



Male cordsets

ASTGH040MSS0005E04

Article no longer available - archive entry



Electrical data		
Operating voltage	[M]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...70
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 42
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 5 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm ² (32 x Ø 0.1 mm)		
Electrical connection - plug		

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated




E11105



Male cordsets

ASTGH040MSS0005E04

Connection

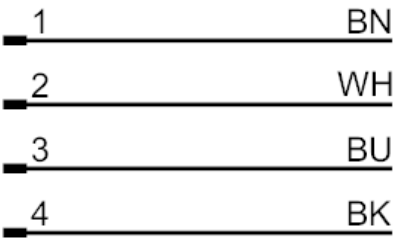

	Core colors :
BK =	black
BN =	brown
BU =	blue
WH =	white