

E11112




Female wirable connectors

SDOAH050MSSFKPG

Article no longer available - archive entry

Alternative articles: E11512
When selecting an alternative article and accessories please note that technical data may differ!

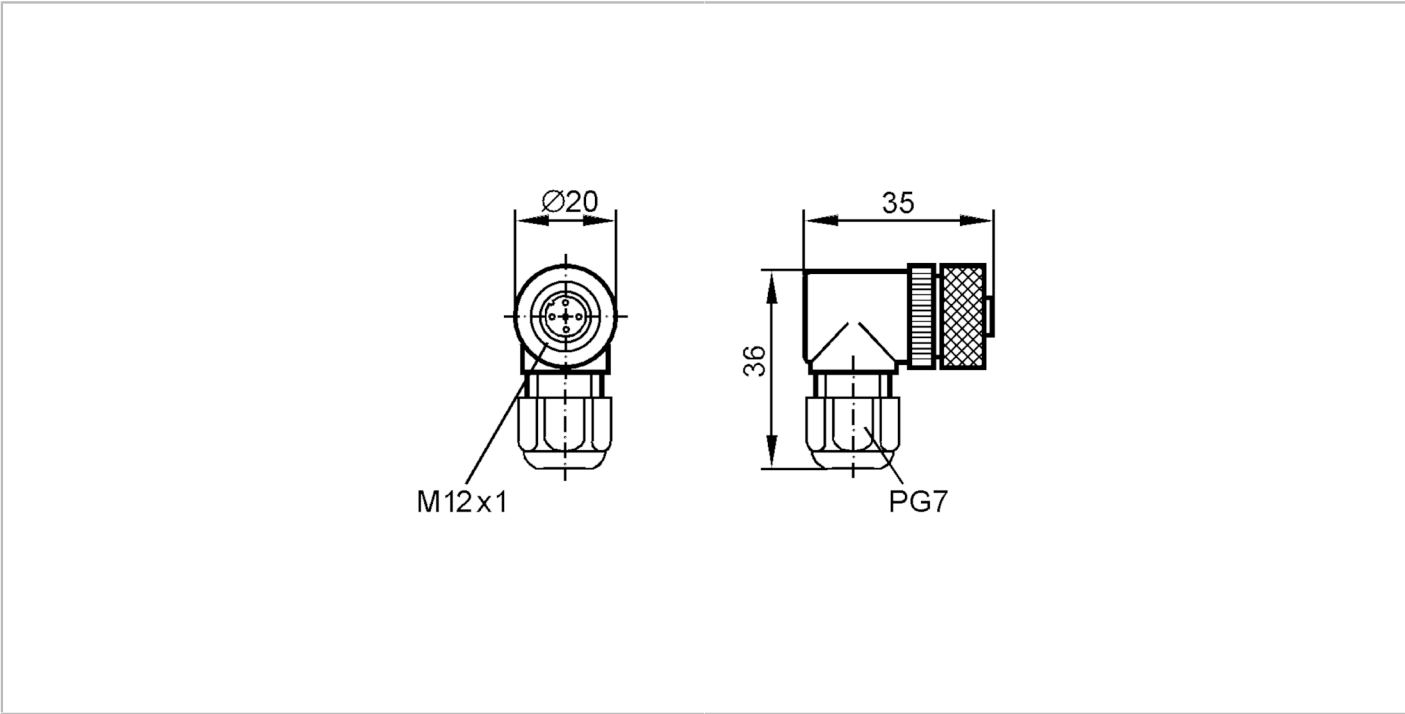

Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	35 x 20 x 36
Material		PA
Molded-body material		PA
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E11112



Female wirable connectors

SDOAH050MSSFKPG

Electrical connection

terminals: ...0.75 mm²; Cable gland: PG 7

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA; Locking: brass, nickel-plated



Connection

