


E11143



Male cordsets

ASTGH050MSS0010H05

Article no longer available - archive entry

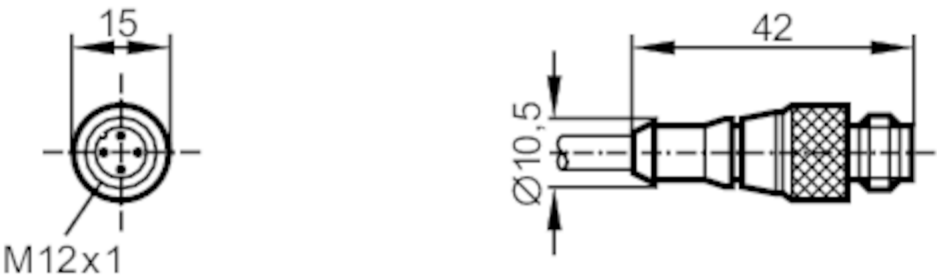

Application	
System	Halogen-free
Electrical data	
Operating voltage	[V] < 30 AC / < 36 DC
Operating conditions	
Ambient temperature	[°C] -25...90
Protection	IP 67
Mechanical data	
Dimensions	[mm] 15 x 15 x 42
Material	TPU (urethane)
Molded-body material	TPU (urethane)
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

E11143



Male cordsets


ASTGH050MSS0010H05

Electrical connection

Cable: 10 m, PUR, Halogen-free, black, Ø 5.6 mm; 5 x 0.5 mm² (16 x Ø 0.2 mm)

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

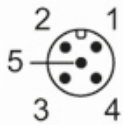

Connection

1	BN
2	WH
3	BU
4	BK
5	GN/YE

	Core colors :
BK =	black
BN =	brown
BU =	blue
GN =	green
WH =	white
YE =	yellow