




Wirable plug

SSTGH040ZDSFKSK

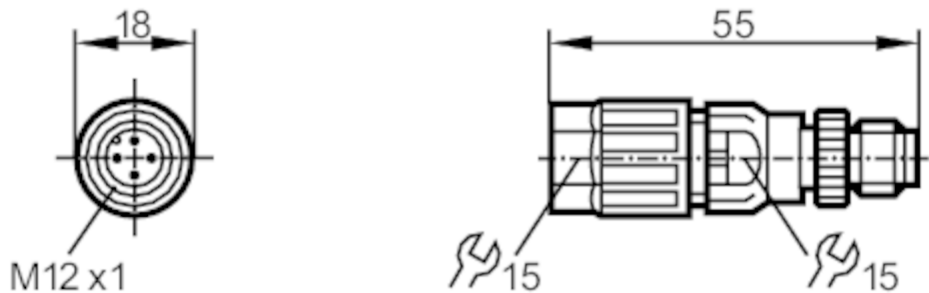

Electrical data

Operating voltage	[V]	< 250 AC/DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...60
Protection		IP 67

Mechanical data

Weight	[g]	15.4
Dimensions	[mm]	18 x 18 x 55
Material		PA 6.6
Molded-body material		PA 6.6
Material nut		zinc, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

insulation displacement technology: 0.34...0.75 mm²; Core insulation: PVC / PE; (Ø ...2.5 mm); Cable sheath: Ø 4...7.5 mm

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PA 6.6; Locking: zinc, nickel-plated



E11144

Wirable plug

SSTGH040ZDSFKSK



Connection

